

Pipe Collar



FEATURES

Clamp for bonding of pipes and exhaust stacks to the lightning protection system

Secures conductor to horizontal or vertical round mounting points

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Conductor Size	Outer Diameter (OD)	Width (W)
SPC5080S	107000		Stainless Steel 18-8 (EN 1.4305)	6 mm Solid - 11 mm Solid	50 - 80 mm	40 mm
SPC5080C	107050	0682632	Copper	6 mm Solid - 11 mm Solid	50 - 80 mm	40 mm
SPC70120S	107010		Stainless Steel 18-8 (EN 1.4305)	6 mm Solid - 11 mm Solid	70 - 120 mm	40 mm
SPC70120C	107060	0682633	Copper	6 mm Solid - 11 mm Solid	70 - 120 mm	40 mm
SPC130180C	107070	0682634	Copper	6 mm Solid - 11 mm Solid	130 - 180 mm	40 mm

Table 2/2

Catalog Number	Article Number	E-Number	Unit Weight
----------------	----------------	----------	-------------

SPC5080S	107000		0.15 kg
SPC5080C	107050	0682632	0.17 kg
SPC70120S	107010		0.17 kg
SPC70120C	107060	0682633	0.19 kg
SPC130180C	107070	0682634	0.24 kg

DIAGRAMS

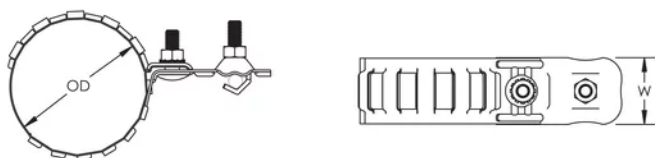

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE