

QCC nVent ERIFLEX Flexibar Clamp



CERTIFICATIONS



FEATURES

Connects nVent ERIFLEX Flexibar to punched busbar

Allows for excellent electrical contact

Compact, space saving design

Installs quickly and easily

Ideal for on site modifications

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/3

Catalog Number	Article Number	E-Number	Conductor Width	Depth (D)	Height (H)	Width (W)
QCC15-5-32	561210	2674263	15.5 - 32 mm	13mm	35 mm	70 mm
QCC40-63	561220	2674266	40 - 63 mm	13mm	35 mm	95 mm

Table 2/3

Catalog Number	Article Number	E-Number	Thickness (T)	A	B	C
QCC15-5-32	561210	2674263	5 mm	50 mm	10.5 mm	11 mm
QCC40-63	561220	2674266	5 mm	75 mm	10.5 mm	11 mm


Table 3/3

Catalog Number	Article Number	E-Number	Unit Weight
QCC15-5-32	561210	2674263	0.11 kg
QCC40-63	561220	2674266	0.16 kg

ADDITIONAL PRODUCT DETAILS

Use one clamp when nVent ERIFLEX Flexibar thickness is less than 5 mm (0.2") and two clamps when nVent ERIFLEX Flexibar thickness is greater than 5 mm (0.2").

DIAGRAMS

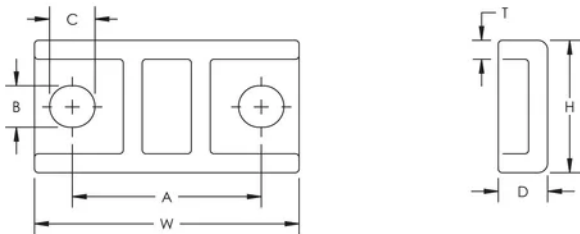

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE