


# Busbar Adapter 80A Without Cables, W060

Universal busbar adapter, with one adjustable mounting rail and with spring terminals 1.5-16 mm<sup>2</sup>.

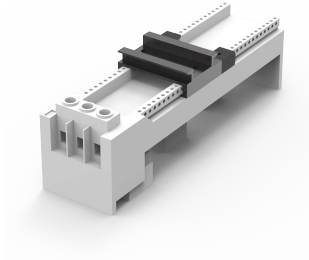

## FEATURES

Description: Busbar adapter 80 A. With one adjustable mounting rail. Without cables, with spring terminals 1.5 - 16 mm<sup>2</sup>.

Rated voltage: 690 V

Rated current: 80 A

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 6 W

Poles: 3-pole

Pack quantity: 1 pc.

SPECIFICATIONS

| Table 1/1      |        |       |       |                     |        |                   |
|----------------|--------|-------|-------|---------------------|--------|-------------------|
| Catalog Number | Height | Width | Depth | Material            | Finish | Color             |
| 32464          | 200mm  | 54mm  | 63mm  | Plastic, Mild Steel | Plated | Black, Light Gray |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE