


Mounting Plates For Power Distribution, MSMPN

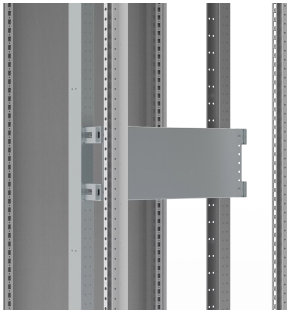

The mounting plate, MSMPN, for fix and modular systems, can be easily machined and have components mounted on it before fixed within the relevant compartment.

FEATURES

Description: Mounting plate for installation of breakers. Suitable for left and right hand connections.

Material: 1.5 mm galvanized steel.

Pack quantity: 1 piece with mounting material.

Mounting requirements: To be assembled on the modular system frame with MSMPA01 or MSMPF01.

SPECIFICATIONS

Finish: Plated

Material: Steel

Table 1/1

Catalog Number	E-Number	Height	Width	Type	Fits Enclosure Size	Panel Size
MSMPN1008H	2504933	10mm	800mm	Horizontal Opening	100 x 800mm	96 x 670mm
MSMPN0506	2504963	50mm	600mm	Plain	50 x 600mm	496 x 470mm
MSMPN0508	2504964	50mm	800mm	Plain	50 x 800mm	496 x 670mm
MSMPN1006	2504932	100mm	600mm	Plain	100 x 600mm	96 x 470mm
MSMPN1006H	2504931	100mm	600mm	Horizontal Opening	100 x 600mm	96 x 470mm
MSMPN1008	2504934	100mm	800mm	Plain	100 x 800mm	96 x 670mm
MSMPN1506	2504936	150mm	600mm	Plain	150 x 600mm	146 x 470mm
MSMPN1506V	2504935	150mm	600mm	Vertical Opening	150 x 600mm	146 x 470mm
MSMPN1508	2504938	150mm	800mm	Plain	150 x 800mm	146 x 670mm
MSMPN1508V	2504937	150mm	800mm	Vertical Opening	150 x 800mm	146 x 670mm
MSMPN2006	2504940	200mm	600mm	Plain	200 x 600mm	196 x 470mm
MSMPN2006V	2504939	200mm	800mm	Vertical Opening	200 x 600mm	196 x 470mm
MSMPN2008	2504942	250mm	600mm	Plain	200 x 800mm	196 x 670mm
MSMPN2008V	2504941	200mm	800mm	Vertical Opening	200 x 800mm	196 x 670mm
MSMPN2506	2504944	250mm	600mm	Plain	250 x 600mm	246 x 470mm
MSMPN2506V	2504943	250mm	600mm	Vertical Opening	250 x 600mm	246 x 470mm
MSMPN2508	2504946	250mm	800mm	Plain	250 x 800mm	246 x 670mm

Catalog Number	E-Number	Height	Width	Type	Fits EnclosureSize	Panel Size
MSMPN2508V	2504945	250mm	800mm	Vertical Opening	250 x 800mm	246 x 670mm
MSMPN3006	2504948	300mm	600mm	Plain	300 x 600mm	296 x 470mm
MSMPN3006V	2504947	300mm	600mm	Vertical Opening	300 x 600mm	296 x 470mm
MSMPN3008	2504950	300mm	800mm	Plain	300 x 800mm	296 x 670mm
MSMPN3008V	2504949	300mm	800mm	Vertical Opening	300 x 800mm	296 x 670mm
MSMPN4006	2504952	400mm	600mm	Plain	400 x 600mm	396 x 470mm
MSMPN4006V	2504951	400mm	600mm	Vertical Opening	400 x 600mm	396 x 470mm
MSMPN4008	2504954	400mm	800mm	Plain	400 x 800mm	396 x 670mm
MSMPN4008V	2504953	400mm	800mm	Vertical Opening	400 x 800mm	396 x 670mm
MSMPN4506	2504956	450mm	600mm	Plain	450 x 600mm	446 x 470mm
MSMPN4506V	2504955	450mm	600mm	Vertical Opening	450 x 600mm	446 x 470mm
MSMPN4508	2504958	450mm	800mm	Plain	450 x 800mm	446 x 670mm
MSMPN4508V	2504957	450mm	800mm	Vertical Opening	450 x 800mm	446 x 670mm
MSMPN5006	2504960	500mm	600mm	Plain	500 x 600mm	496 x 470mm
MSMPN5008	2504962	500mm	800mm	Plain	500 x 800mm	496 x 670mm
MSMPN6006	2504967	600mm	600mm	Plain	600 x 600mm	596 x 470mm
MSMPN6006V	2504966	600mm	600mm	Vertical Opening	600 x 600mm	596 x 470mm
MSMPN6008	2504969	600mm	800mm	Plain	600 x 800mm	596 x 670mm
MSMPN6008V	2504968	600mm	1000mm	Vertical Opening	600 x 800mm	596 x 670mm
MSMPN6010	2504965	600mm	1000mm	Plain	600 x 1000mm	596 x 870mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE