


Mounting Profiles 19-Inch , CIP

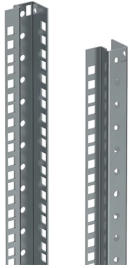

19" equipment can be easily fitted in floor standing enclosures, either in the factory or in the field, when these profiles are used.

FEATURES

Description: Full height mounting profiles to achieve 482.6 mm (19") mounting requirements on all sides. Fully adjustable in depth.

Material: 2 mm zinc plated steel.

Pack quantity: 1 pair.

Mounting requirements: To be used in conjunction with CIB or CID profiles. For partial height mounting the CIWR is required.

SPECIFICATIONS

Thickness: 2mm
Material: Mild Steel
Finish: Zinc Plated

Table 1/1

Catalog Number	E-Number	Height	Width	Depth	Rack Units	Enclosure Material
CIP20	2502493	1000mm	45mm	29mm	20U	Mild Steel
CIP22	2502494	1100mm	45mm	29mm	22U	Mild Steel
CIP24	2502495	1200mm	45mm	29mm	24U	Mild Steel
CIP29	2502496	1400mm	45mm	29mm	29U	Mild Steel
CIP33	2502497	1600mm	45mm	29mm	33U	Mild Steel
CIP38	2515398	1800mm	45mm	29mm	38U	Mild Steel
CIP42	2513675	2000mm	45mm	29mm	42U	Mild Steel
CIP47	2502498	2200mm	45mm	29mm	47U	Mild Steel

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE