


## Varistar CP Swing Frame for 600 mm Width

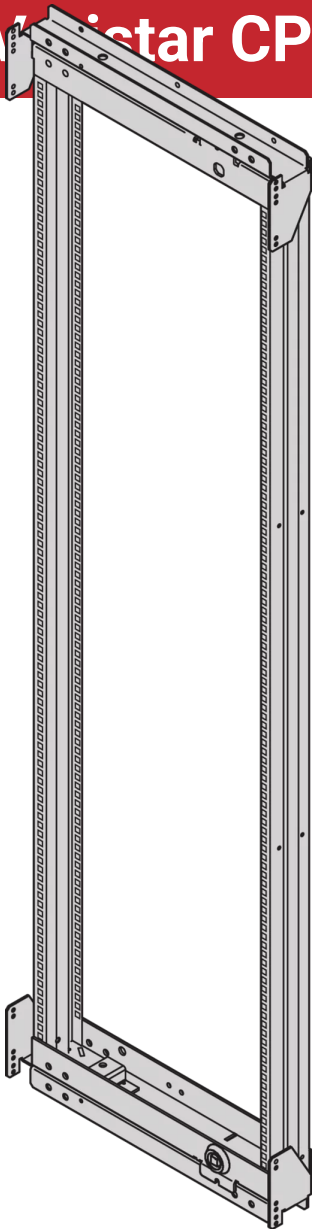

The 19" swing frame allows the installation of sub-racks while simultaneously making wiring at the rear accessible.

Varistar CP swing frame comes with 150 KG load capacity, 120° movement and flexible pivot point.

### FEATURES

For full height or partial-height mounting

Pivot point can be selected right or left

Can accommodate 19" chassis and 19" subracks (maximum depth 200 mm)

120° hinge, square locks including 2 keys

Load-carrying capacity 150 kg

## SPECIFICATIONS

<b>Width:</b>	600mm
<b>Product Type:</b>	Cabinet/Rack Frame
<b>Material:</b>	Steel

Table 1/2

Catalog Number	Rack Height	Package Quantity	Color	Color Code	Finish	Height
21630-668	24U	1	Black Grey	RAL 7021	Powder Coated	1200mm
21630-670	29U	1	Black Grey	RAL 7021	Powder Coated	1400mm
21630-672	33U	1	Black Grey	RAL 7021	Powder Coated	1600mm
21630-674	38U	1	Black Grey	RAL 7021	Powder Coated	1800mm
21630-676	42U	1	Black Grey	RAL 7021	Powder Coated	2000mm
21630-678	47U	1	Black Grey	RAL 7021	Powder Coated	2200mm

Table 2/2

Catalog Number	Protection Rating	Quick Ship
21630-668	IP20	No
21630-670	IP20	No
21630-672	IP20	No
21630-674	IP20	No
21630-676	IP20	No
21630-678	IP20	No

ADDITIONAL PRODUCT DETAILS

By aid of depth members 19" swing frames can be assembled directly on the cabinet frame or in depth-adjustable increments of 50 mm.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE