

# C-EC Cable to Strut Clamp, 60–64 mm OD

## CATALOG NUMBER

---

**C64EC**



## FEATURES

---

One-piece cable/conduit clamp with protective boot

No screws or bolts to drop

Requires only a screwdriver or nutdriver for installation

Fits into open side of strut channel

## PRODUCT ATTRIBUTES

---

Article Number: 337730

Material: Steel

Finish: Hot-Dip Galvanized

Outer Diameter (OD): 60 - 64 mm

Width (W): 30 mm

Thickness (T): 2.25 mm

Torque (TQ): 4 N·m

A: 18 mm Min


B: 10 mm Max

## ADDITIONAL PRODUCT DETAILS

---

Screw is electrogalvanized on clamps that have an outer diameter of 40 mm or less.

## DIAGRAMS

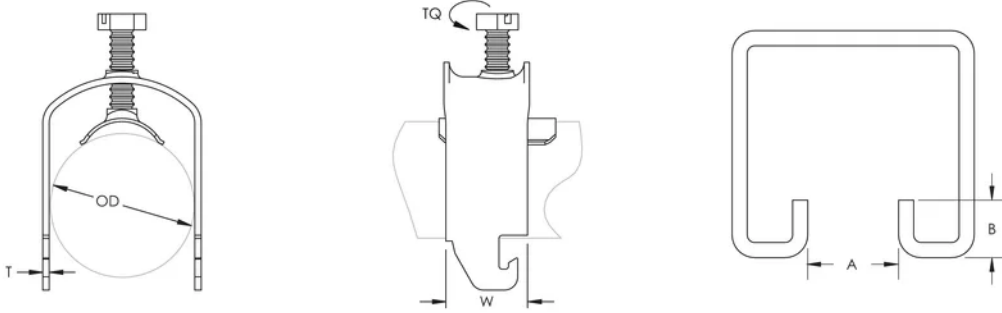

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

