

nVent CADDY Speed Link SLK with Angle Bracket



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled angle bracket end fitting

Ideal for attaching to concrete, steel or wood surfaces

Simple alternative to jack chain and additional hardware

SPECIFICATIONS

Static Load Safety Factor:	5:1
Finish:	Electrogalvanized
Material:	Steel;Zinc Alloy;Polypropylene
Complies With:	SMACNA HVAC-DCS


Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)
SLK2L3AB	196530	2 mm	3m	22.6 mm	7.1 mm	55 mm

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope Length	A	Hole Size (HS)	Height (H)
SLK2L5AB	196531	2 mm	5m	22.6 mm	7.1 mm	55 mm
SLK3L10AB	196716	3 mm	10m	22.6 mm	7.1 mm	62 mm

Table 2/2						
Catalog Number	Article Number	Width (W)	Thickness (T)	Angle (a)	Static Load	Certifications
SLK2L3AB	196530	19 mm	12.5 mm	90 ° Max	440N	ITB, UL, cUL
SLK2L5AB	196531	19 mm	12.5 mm	90 ° Max	440N	UL, cUL, ITB
SLK3L10AB	196716	24 mm	16 mm	90 ° Max	890N	

DIAGRAMS

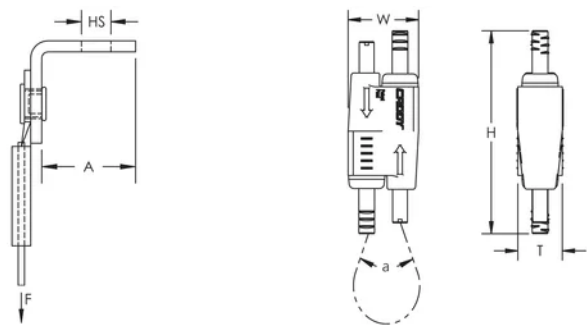

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

