


# WBT Performance Cable Tray Blind End

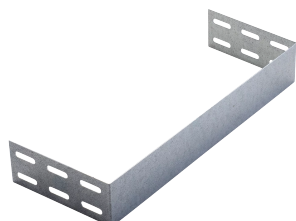

The nVent CADDY WBT Performance Cable Tray Blind End is used for terminal ends of cable tray that cannot be open. Fasten the blind end to the open end of wire basket tray to act as a barrier stop and serve as the end of a section.

## FEATURES

Builds stability and creates an aesthetically clean end of tray

Can be used to secure an electrical box to side of tray

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/1

Catalog Number	Height	Width	Length	Unit Weight
WBTBE2X4	50.8 mm	101.6 mm	119.46mm	0.454 kg
WBTBE2X6	50.8 mm	152.4 mm	170.26mm	0.454 kg
WBTBE2X8	50.8 mm	203.2 mm	221.06mm	0.454 kg
WBTBE4X4	101.6 mm	101.6 mm	119.46mm	0.454 kg
WBTBE4X6	101.6 mm	152.4 mm	170.26mm	0.454 kg
WBTBE4X8	101.6 mm	203.2 mm	221.06mm	0.454 kg

Catalog Number	Height	Width	Length	Unit Weight
WBTBE6X8	152.4 mm	203.2 mm	221.06mm	0.454 kg
WBTBE2X12	50.8 mm	304.8 mm	322.66mm	0.907 kg
WBTBE2X16	50.8 mm	406.4 mm	424.26mm	0.907 kg
WBTBE4X12	101.6 mm	304.8 mm	322.66mm	0.907 kg
WBTBE4X16	101.6 mm	406.4 mm	424.26mm	0.907 kg
WBTBE6X12	152.4 mm	304.8 mm	322.66mm	0.907 kg
WBTBE6X16	152.4 mm	406.4 mm	424.26mm	0.907 kg
WBTBE2X18	50.8 mm	457.2 mm	475.06mm	1.361 kg
WBTBE2X20	50.8 mm	508 mm	525.86mm	1.361 kg
WBTBE2X24	50.8 mm	609.6 mm	627.46mm	1.361 kg
WBTBE4X18	101.6 mm	457.2 mm	475.06mm	1.361 kg
WBTBE4X20	101.6 mm	508 mm	525.86mm	1.361 kg
WBTBE4X24	101.6 mm	609.6 mm	627.46mm	1.361 kg
WBTBE6X18	152.4 mm	457.2 mm	475.06mm	1.361 kg
WBTBE6X20	152.4 mm	508 mm	525.86mm	1.361 kg
WBTBE6X24	152.4 mm	609.6 mm	627.46mm	1.361 kg

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

