
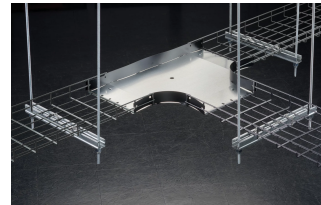


# WBT Performance Cable Tray PreForm Tee

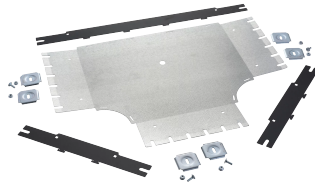

nVent CADDY WBT Performance Cable Tray PreForm is a cleaner, faster, more uniform engineered solution for pathway bends, tees and intersections. The PreForm Tee is a revolutionary, time-saving solution for seamless intersections ensuring clean engineering precision and effortless attachment without cutting or configuring. Due to its unique design, this offering provides up to 60% reduction in labor and time compared to traditional methods while maintaining flexibility and cost-effectiveness in tray pathway retrofits.

## FEATURES

Routes cable systems in two directions

Maintains UL classification throughout installation

## SPECIFICATIONS

**Finish:** Pregalvanized

**Material:** Steel

Table 1/1

| Catalog Number | Color | Height  | Width     | Length   | Unit Weight |
|----------------|-------|---------|-----------|----------|-------------|
| WBTT2X4        |       | 50.8 mm | 94.46 mm  | 526.26mm | 0.454 kg    |
| WBTT2X4BA      | Black | 50.8 mm | 94.46 mm  | 526.26mm | 0.454 kg    |
| WBTT2X6        |       | 50.8 mm | 144.48 mm | 576.28mm | 1.361 kg    |
| WBTT2X6BA      | Black | 50.8 mm | 144.48 mm | 576.28mm | 1.361 kg    |

| Catalog Number | Color | Height  | Width     | Length    | Unit Weight |
|----------------|-------|---------|-----------|-----------|-------------|
| WBTT2X12       |       | 50.8 mm | 294.49 mm | 726.29mm  | 2.722 kg    |
| WBTT2X12BA     | Black | 50.8 mm | 294.49 mm | 726.29mm  | 2.722 kg    |
| WBTT2X18       |       | 50.8 mm | 444.5 mm  | 876.3mm   | 4.536 kg    |
| WBTT2X18BA     | Black | 50.8 mm | 444.5 mm  | 876.3mm   | 4.536 kg    |
| WBTT2X24       |       | 50.8 mm | 594.51 mm | 1026.31mm | 7.257 kg    |
| WBTT2X24BA     | Black | 50.8 mm | 594.51 mm | 1026.31mm | 7.257 kg    |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

