


# Side Panel, SPMS, 1764x18x462mm, Brushed, Stainless Steel 304

## CATALOG NUMBER

**SPMS1805**

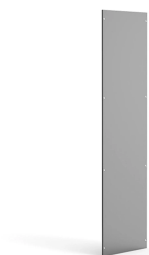

These side panels will ensure that the ingress protection is maintained, which means that the electrical components will operate without any disturbances and protect personnel from injuries.

## FEATURES

Description: Easy one man assembly. Sealed by an extruded, one piece polyurethane gasket and mounted with 8 screws and new patented retainers.

Protection: IP 55, TYPE 12, 13 in combination with MCSS. IP66, TYPE 4X, 12 in combination with MCSS-HP.

Pack quantity: 2 panels with mounting accessories.

Material: 1.5 mm AISI 304 / AISI 316L pre-grained stainless steel.

Finish: 400 pre-grained stainless steel.

## PRODUCT ATTRIBUTES

Article Number: SPMS1805

Height: 1764mm

Width: 18mm

Depth: 462mm

Material: Stainless Steel 304

Finish: Brushed

Thickness: 1.5mm

Product Family: Free-Standing

Enclosure Material: Mild Steel

Package Quantity: 2

Weight: 21.7kg

## **WARNING**

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**