


# Split Bottom Plates Stainless Steel, CBPS

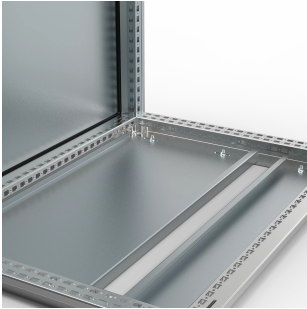

A split bottom plate offers a flexible cabling solution and eliminates the need for individual cable glands. The protection degree is maintained by using a separate gasket.

## FEATURES

---

Description: Fitted in place of the standard one piece bottom plate, allows direct cable entry. To achieve perfect sealing around the cables use the gasket kit BG01.

Material: AISI 304 / AISI 316L pre-grained stainless steel.

Bottom plates: 1.5 mm.

Finish: 400 pre-grained stainless steel.

Pack quantity: 1 kit of two part bottom plate.

## SPECIFICATIONS

**Thickness:** 1.5mm  
**Finish:** Brushed

Table 1/1

| Catalog Number | Height | Width  | Depth | Enclosure Material | Material            | Quick Ship |
|----------------|--------|--------|-------|--------------------|---------------------|------------|
| CBPS0640       | 25mm   | 600mm  | 400mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0640-316   | 25mm   | 600mm  | 400mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS0650       | 25mm   | 600mm  | 500mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0650-316   | 25mm   | 600mm  | 500mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS0660       | 25mm   | 600mm  | 600mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0660-316   | 25mm   | 600mm  | 600mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS0840       | 25mm   | 800mm  | 400mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0840-316   | 25mm   | 800mm  | 400mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS0850       | 25mm   | 800mm  | 500mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0850-316   | 25mm   | 800mm  | 500mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS0860       | 25mm   | 800mm  | 600mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS0860-316   | 25mm   | 800mm  | 600mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS1040       | 25mm   | 1000mm | 400mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS1040-316   | 25mm   | 1000mm | 400mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS1050       | 25mm   | 1000mm | 500mm | Stainless Steel    | Stainless Steel 304 | No         |
| CBPS1050-316   | 25mm   | 1000mm | 500mm | Stainless Steel    | Stainless Steel 316 | No         |
| CBPS1060       | 25mm   | 1000mm | 600mm | Stainless Steel    | Stainless Steel 304 | No         |

| Catalog Number | Height | Width  | Depth | EnclosureMaterial | Material            | Quick Ship |
|----------------|--------|--------|-------|-------------------|---------------------|------------|
| CBPS1060-316   | 25mm   | 1000mm | 600mm | Stainless Steel   | Stainless Steel 316 | No         |

### ADDITIONAL PRODUCT DETAILS

For enclosures 1200 mm & 1600 mm wide use 2 x 600 mm & 2 x 800 mm wide bottom plates.

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE