


# Switch Disconnecter, WO60

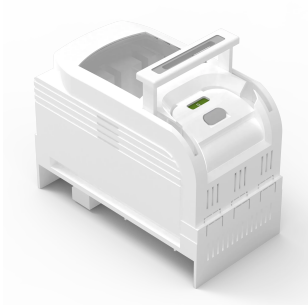

Spring controlled switch disconnecter without fuses.

## INDUSTRY STANDARDS

---

IEC  
VDE  
DNV-GL

## FEATURES

---

Description: 3-pole switch disconnecter. With multifunction handle (snap action switch mechanism). Connection at the bottom.

Rated voltage: 690 V

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 26,7 W

Pack quantity: 1 pc.

Approvals: IEC, VDE, DNV GL

Connection at the bottom

Rated voltage: 690 V

For busbars: 12, 15, 20, 25, 30 × 5, 10

Power dissipation at 80% load: 26,7 W

SPECIFICATIONS

| Table 1/1      |        |       |       |                |        |            |
|----------------|--------|-------|-------|----------------|--------|------------|
| Catalog Number | Height | Width | Depth | Material       | Finish | Color      |
| 33540          | 200mm  | 106mm | 176mm | Plastic, Steel | Smooth | Light Gray |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE