


# HF Frame Type Plug-In Unit Slide Nut, M2.5; 100 pieces

## CATALOG NUMBER

**21100-112**

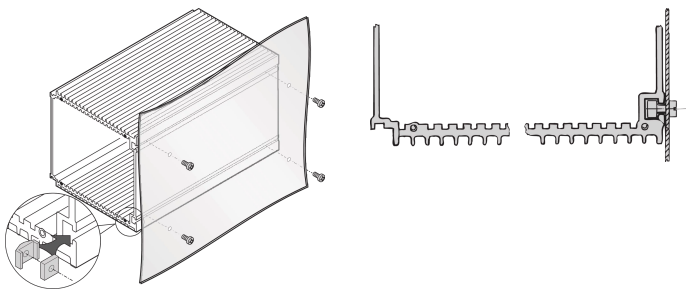

The slide nut can be inserted into the grooves of the HF tube and enable a user to assemble the tube.

## CERTIFICATIONS



## FEATURES

Alternative for threaded insert

## PRODUCT ATTRIBUTES

Package Quantity: 100

Depth (D): 5.5mm

Finish: Zinc Plated

Height (H): 12mm

Material: Steel; Polyamide 6

Product Type: Nut

Type: Slide Nut

Width (W): 7mm


Works With: Frame Type Plug-In Unit

Net Weight: 0.079kg

Thread Size (TS): M2.5

Thread Type: Metric

## DIAGRAMS

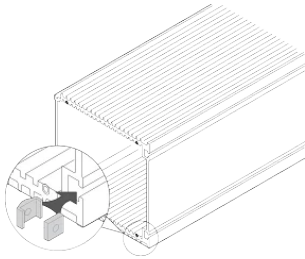

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**