 


EuropacPRO 19" Subrack Kit for Backplane, Shielded

EMC Shielded subrack for backplane mounting, rear side covered by a rear panel.



CERTIFICATIONS



FEATURES

Subrack with side panel type F ("flexible"), front 19" bracket included, depth-adjustable 19" bracket sold separately (not included in items delivered)

Supplied as space-saving flat-pack

Modifications such as cutouts, different finishes or dimensions available

EMC of approximately 40 dB at 1 GHz, 30 dB at 2 GHz, assuming that the front is covered with shielded front panels, testing in accordance with VG 95373 part 15

IP 20, in accordance with IEC 60529

Aluminum construction

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Rear horizontal rail for backplane mounting with insulation strip

Horizontal rail type "light"

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated

Product Type: Subrack/Chassis

EMC Shielding: Yes

Table 1/2

Catalog Number	Rack Height	Depth (D)	Package Quantity	For Mounting	Board Depth	Gasket Type
24563-142	3U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-143	3U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-144	3U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-145	3U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-146	3U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-442	6U	235mm	1	Backplane	160mm, 220mm	Textile EMC
24563-443	6U	295mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-444	6U	355mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-445	6U	415mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC
24563-446	6U	475mm	1	Backplane	160mm, 220mm, 280mm	Textile EMC

Table 2/2


Catalog Number	Handle Included	Mounting	Complies With	Rack Width	Static Load	Quick Ship
24563-142	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-143	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-144	No	Rack	IEC 60297-3-103	84HP	11kg	No

CatalogNumber	HandleIncluded	Mounting	Complies With	Rack Width	Static Load	Quick Ship
24563-145	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-146	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-442	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-443	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-444	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-445	No	Rack	IEC 60297-3-103	84HP	11kg	No
24563-446	No	Rack	IEC 60297-3-103	84HP	11kg	No

ADDITIONAL PRODUCT DETAILS

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

DIAGRAMS

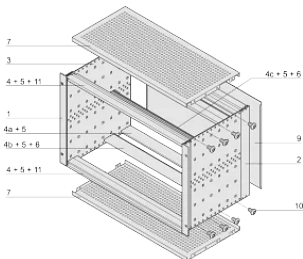

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE