

# Plug-In Unit Kit With IEL Handle for Rear I/O, Shielded, Black



Plug-in unit, with IEL inserter/extractor black handle, 3 U, rear I / O assembly. The U-shaped front panel enable shielding with a textile gasket.

## CERTIFICATIONS



## FEATURES

U-shaped front panel for textile gasket

Suitable for insertion and extraction forces up to 700 N (per pair)

Enable the installation of a microswitch

Enable the installation of coding pegs in accordance with IEC 60297-3-103/ IEEE 1101.10

## SPECIFICATIONS

<b>Rack Height:</b>	3U
<b>Material:</b>	Aluminum
<b>Finish:</b>	Anodized; Passivated
<b>Product Type:</b>	Front Panel
<b>Type:</b>	Front Panel with Handle (PIU)
<b>EMC Shielding:</b>	Yes


Table 1/2

Catalog Number	Rack Width	Package Quantity	Handle Type	Mounting	Gasket Type	Front Finish
20848-751	4HP	1	IEL	Screw-on Rear IO	Textile EMC	Anodized
20848-752	8HP	1	IEL	Screw-on Rear IO	Textile EMC	Anodized

Table 2/2

Catalog Number	Rear Finish	Treated Edges	Complies With	Height (H)	Width (W)	Quick Ship
20848-751	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	128.4mm	20mm	No
20848-752	Etched	No	IEC 60297-3-102, IEEE 1101.10, IEC 60297-3-103, IEEE 1101.1/11	128.4mm	40.3mm	No

## DIAGRAMS

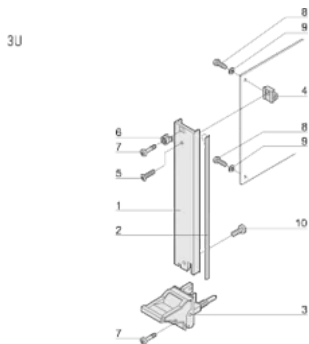

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**