


# nVent CADDY Speed Link Light Pack Spool Kit

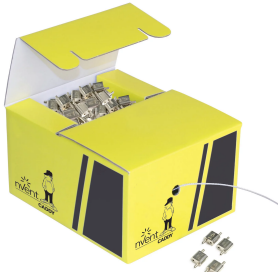

The nVent CADDY Speed Link Light Pack Spool Kit includes a 150-meter long spool of 1mm wire rope together with 100 ultra-low-profile locking devices. The smart packaging allows contractors to pull and cut the wire length needed without having to take the spool out of the box, making it an ideal solution for every electrician to have on hand. The locking device has an aesthetic polished finish and a 10-kilogram load rating, ideal for supporting and securing lighting and signage.

## FEATURES

Kit includes spool of nVent CADDY Speed Link steel wire and nVent CADDY Speed Link CLP locking devices

Wire spool and locking devices are packaged together, simplifying transportation to the jobsite and reducing inventory

Packaging allows end-users to pull and cut any length of wire that is needed without having to take the spool out of the box

Ideal for rework and installations where custom lengths of wire may be needed

Wire rope constructed from seven bundles of seven strands each of steel aircraft wire

Keyless release allows easy adjustments

Low-profile locking device minimizes visual impact

Keyless release tubes are easy to operate while wearing gloves

Double-sided locking mechanism enables simple height adjustment

## SPECIFICATIONS

Table 1/1

| Catalog Number | Article Number | Finish            | Material     | Wire Rope Diameter | Length | Number of Locking Devices |
|----------------|----------------|-------------------|--------------|--------------------|--------|---------------------------|
| CLP1L500PACK   | 196095         | Electrogalvanized | Steel, Brass | 1 mm               | 150m   | 100                       |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

