


# EuropacPRO Advanced EMC Plus, Dual Mesh Top and Bottom Covers, Screwed to Side Panel

NEW PRODUCT

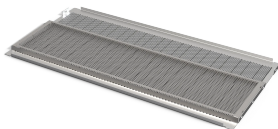

A cover plate is used for electromagnetic shielding and as mechanical protection. The cover can be screwed onto the side panel.

## FEATURES

Dual mesh top and bottom covers with EMC and airflow optimized perforation, for highest RF-shielding requirements

Fulfills the requirements of the fire safety standard EN 62368-1

For PCBs with standard formats

Cover plate for bolting to the side panel

Suitable for use with all horizontal rails, besides Rugged

## SPECIFICATIONS

|                        |             |
|------------------------|-------------|
| <b>Material:</b>       | Aluminum    |
| <b>Product Type:</b>   | Cover Plate |
| <b>Product Family:</b> | EuropacPRO  |
| <b>Finish:</b>         | Passivated  |
| <b>Type:</b>           | Perforated  |
| <b>Works With:</b>     | Sub racks   |

Table 1/1

| Catalog Number | Depth | Package Quantity | Rack Width | Board Depth | Package Unit | Quick Ship |
|----------------|-------|------------------|------------|-------------|--------------|------------|
| 24563-770      | 175mm | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-771      | 235mm | 2                | 84HP       | 160mm       | Pair         | No         |

| CatalogNumber | Depth    | Package Quantity | Rack Width | Board Depth | Package Unit | Quick Ship |
|---------------|----------|------------------|------------|-------------|--------------|------------|
| 24563-772     | 275mm    | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-773     | 277.75mm | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-774     | 295mm    | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-775     | 355mm    | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-776     | 415mm    | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-777     | 475mm    | 2                | 84HP       | 160mm       | Pair         | No         |
| 24563-780     | 235mm    | 2                | 84HP       | 220mm       | Pair         | No         |
| 24563-781     | 295mm    | 2                | 84HP       | 220mm       | Pair         | No         |
| 24563-782     | 355mm    | 2                | 84HP       | 220mm       | Pair         | No         |
| 24563-783     | 415mm    | 2                | 84HP       | 220mm       | Pair         | No         |
| 24563-784     | 475mm    | 2                | 84HP       | 220mm       | Pair         | No         |
| 24563-790     | 295mm    | 2                | 84HP       | 280mm       | Pair         | No         |
| 24563-791     | 355mm    | 2                | 84HP       | 280mm       | Pair         | No         |
| 24563-792     | 415mm    | 2                | 84HP       | 280mm       | Pair         | No         |
| 24563-793     | 475mm    | 2                | 84HP       | 280mm       | Pair         | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**