


PropacPRO Rear Hood

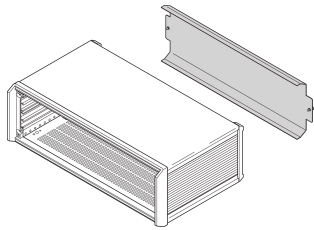

The rear hood can be assembled onto a rear panel of a PropacPRO case. The rear hood enables an additional space between the rear panel and the hood to provide space to store a cable. Can be unscrewed from the rear side.

CERTIFICATIONS



FEATURES

Al material 1.0 mm, RAL 9006

The fixing is done with two knurled screws

SPECIFICATIONS

Material:	Aluminum
Works With:	Cases
Product Type:	Cover
Finish:	Powder Coated
Product Family:	PropacPRO
Type:	Rear Hood

Table 1/1

Catalog Number	Rack Height	Rack Width	Package Quantity	Quick Ship
24576-086	3U	42HP	1	No
24576-088	3U	84HP	1	No
24576-092	4U	84HP	1	No

Catalog Number	Rack Height	Rack Width	Package Quantity	Quick Ship
24576-087	3U	63HP	1	No
24576-091	4U	63HP	1	No

ADDITIONAL PRODUCT DETAILS

To install the rear hood, feet must be fitted to the rear panel; please order separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE