

nVent CADDY Cat HP J-Hook Bracket with Shot-Fire Bracket



FEATURES

Link to J-Hooks in one of multiple color options to aid in pathway identification and organization

Complete with shot-fire bracket and pre-assembled drive pin from DEWALT®

Quickly and easily attaches to concrete, steel or composite metal decking

Integrated pin installs easily using powder-actuated or single-shot gas-actuated tools

J-Hooks feature bendable locking tabs that lock on to nVent CADDY Cat HP components to provide rigidity and stability

Customized J-Hook trees can be easily assembled with various J-Hook sizes, colors and configurations

nVent CADDY Cat HP components easily attach to any size nVent CADDY Cat HP J-Hook

ICC-ES ESR-2024 evaluation report available for drive pin from DEWALT®

SPECIFICATIONS


Table 1/1

Catalog Number	Article Number	Material	Finish	Width (W)	A	Static Load
CATHPABSF	181678	Steel, Spring Steel	Electrogalvanized, nVent CADDY Armour	39.7 mm	33 mm	440N

ADDITIONAL PRODUCT DETAILS

For shot-fired supports in seismic design category D, E, or F, maximum load is the lesser of 90 lb (400 N) or the published load.

DIAGRAMS

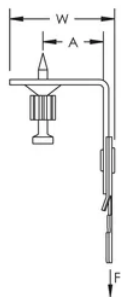

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

