


# CableTek Horizontal Cable Manager

## Data Solutions

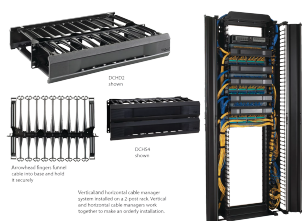

The CableTek Horizontal Cable Manager features heavy-duty endposts, arrowhead fingers and tool-less mounting to easily route Cat 5e, 6 and 6A cable horizontally in standard 19-in. cabinets or on 2- or 4-post open frame racks.

### INDUSTRY STANDARDS

EIA 310-D

### FEATURES

Snap-in mounting provision holds cable manager in place while mounting screws are installed

Robust arrowhead fingers are shaped to funnel cables into base and are made of black composite material

Robust rounded end posts support cable as it enters and leaves cable manager and maintains proper cable bend radius

Deep cable compartments allow maximum cable density

Rounded edges throughout protect cable jackets from damage

Pass-through holes on double-sided models protect cable while facilitating routing between front and back sides

Single- and double-sided units provide high cable capacity, including 5e, 6 and 6A cables

1 RU and 2 RU heights allow greater flexibility in optimizing rack capacity

Removable hinged cover opens top or bottom, snaps closed for assured cable protection and professional appearance

Double-sided model has covers on both front and back

Covers stay open during installation and maintenance procedures

Horizontal and vertical cable managers designed as a system for streamlined appearance and improved functionality

Combination head 10-32 and 12-24 screws included for mounting

Made of UL listed black composite material

### SPECIFICATIONS

Table 1/3

| Catalog Number | Article Number | Height | Width | Depth | Material | Finish |
|----------------|----------------|--------|-------|-------|----------|--------|
|----------------|----------------|--------|-------|-------|----------|--------|

|       |       |       |      |       |     |              |
|-------|-------|-------|------|-------|-----|--------------|
| DCHS1 | 17241 |       |      |       | ABS | Smooth Matte |
| DCHS2 | 17242 | 201mm | 88mm | 481mm | ABS | Smooth Matte |
| DCHD2 | 17243 |       |      |       | ABS | Smooth Matte |
| DCHS4 | 26292 |       |      |       | ABS | Smooth Matte |

Table 2/3

| Catalog Number | Article Number | Color     | Color Code | Fill Rate, Back Cable, Cat 5e<br>0.22 in | Fill Rate, Back Cable, Cat 6<br>0.25 in | Fill Rate, Back Cable, Cat 6A<br>0.30 in |
|----------------|----------------|-----------|------------|------------------------------------------|-----------------------------------------|------------------------------------------|
| DCHS1          | 17241          | Jet Black | RAL 9005   |                                          |                                         |                                          |
| DCHS2          | 17242          | Jet Black | RAL 9005   |                                          |                                         |                                          |
| DCHD2          | 17243          | Jet Black | RAL 9005   | 223                                      | 172                                     | 119                                      |
| DCHS4          | 26292          | Jet Black | RAL 9005   |                                          |                                         |                                          |

Table 3/3

| Catalog Number | Article Number | Rack Units | Fill Rate, Front Cable, Cat 5e<br>0.22 in | Fill Rate, Front Cable, Cat 6<br>0.25 in | Fill Rate, Front Cable, Cat 6A<br>0.30 in |
|----------------|----------------|------------|-------------------------------------------|------------------------------------------|-------------------------------------------|
| DCHS1          | 17241          | 1U         | 66                                        | 57                                       | 35                                        |
| DCHS2          | 17242          | 2U         | 208                                       | 161                                      | 112                                       |
| DCHD2          | 17243          | 2U         | 208                                       | 161                                      | 112                                       |
| DCHS4          | 26292          | 4U         | 416                                       | 322                                      | 224                                       |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**