


Busbar to Busbar

Data Solutions

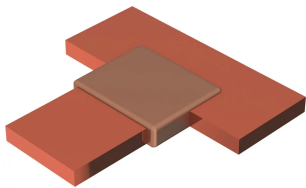

nVent ERICO Cadweld graphite molds are designed and engineered for thousands of connection styles and conductor combinations.

CERTIFICATIONS



FEATURES

Forms a permanent, low resistance connection

Provides a molecular bond

nVent ERICO Cadweld Exothermic Connections are rated with the same current capacity as the conductor

Portable installation equipment with no external source of power required

Installers can be easily trained to make nVent ERICO Cadweld Exothermic Connections

Connections can be visually inspected

SPECIFICATIONS

Table 1/1

Catalog Number	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BBCAF		BB Mold Family	1/16" x 1 1/4"	1/16" x 1 1/4"		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMDEHAH		BM Mold Family	1/4" x 2"	1/16" x 2"		
BAKJN		BA Mold Family	1/2" x 5"	1/2" x 5"		
BAKJNM		BA Mold Family	1/2" x 5"	1/2" x 5"		
BBKJN		BB Mold Family	1/2" x 5"	1/2" x 5"		
BBKJNM		BB Mold Family	1/2" x 5"	1/2" x 5"		
BBCEG		BB Mold Family	1/4" x 1 1/2"	1/4" x 1 1/2"		
BBCEF		BB Mold Family	1/4" x 1 1/4"	1/4" x 1 1/4"		
BMCEHEF		BM Mold Family	1/4" x 2"	1/4" x 1 1/4"		
BQCEHEE		BQ Mold Family	1/4" x 2"	1/4" x 1"		
ENCEEEE		EN Mold Family	1/4" x 1"	1/4" x 1"		
EPCEE		EP Mold Family	1/4" x 1"	1/4" x 1"		cUL, UL
BKCEEEE		BK Mold Family	1/4" x 1"	1/4" x 1"		
BACEE		BA Mold Family	1/4" x 1"	1/4" x 1"		cUL, UL
BACEH		BA Mold Family	1/4" x 2"	1/4" x 2"		cUL, UL
BBDEHEH		BB Mold Family	1/4" x 2"	1/4" x 2"		
EEREHEH		EE Mold Family	1/4" x 2" and wider	1/4" x 2"		
ENDEHEH		EN Mold Family	1/4" x 2"	1/4" x 2"		
EPCEH		EP Mold Family	1/4" x 2"	1/4" x 2" and wider		UL, cUL

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMDEHCH		BM Mold Family	1/4" x 2"	1/8" x 2"		
BMDEHEH		BM Mold Family	1/4" x 2"	1/4" x 2"		
BQCEHCE		BQ Mold Family	1/4" x 2"	1/8" x 1"		
BQDEHEH		BQ Mold Family	1/4" x 2" and wider	1/4" x 2"		
BTJEHCH		BT Mold Family	1/4" x 2"	1/8" x 2"		
BTJEHEH		BT Mold Family	1/4" x 2"	1/4" x 2"		
BVJEHEH		BV Mold Family	1/4" x 2" and wider	1/4" x 2"		
BDEEHM		BD Mold Family	1/4" x 2"	1/4" x 2"		
EBCEHEH		EB Mold Family	1/4" x 2" and wider	1/4" x 2" and wider		
BMDEKEK		BM Mold Family	1/4" x 3" and wider	1/4" x 3"		
BQDEKEK		BQ Mold Family	1/4" x 3"	1/4" x 3"		
BADEK		BA Mold Family	1/4" x 3"	1/4" x 3"		cUL, UL
BBFEK		BB Mold Family	1/4" x 3"	1/4" x 3"		
BMKEMEM		BM Mold Family	1/4" x 4" and wider	1/4" x 4"		
BADEM		BA Mold Family	1/4" x 4"	1/4" x 4"		cUL, UL
ENKEMEMM		EN Mold Family	1/4" x 4" and wider	1/4" x 4"		
EPDEM		EP Mold Family	1/4" x 4"	1/4" x 4" and wider		cUL, UL
EERCECE		EE Mold Family	1/8" x 1"	1/8" x 1"		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
ENCCECE		EN Mold Family	1/8" x 1"	1/8" x 1"		
EPCCE		EP Mold Family	1/8" x 1"	1/8" x 1"		cUL, UL
BMCCECE		BM Mold Family	1/8" x 1"	1/8" x 1"		
BACCE		BA Mold Family	1/8" x 1"	1/8" x 1"		UL, cUL
BBCCE		BB Mold Family	1/8" x 1"	1/8" x 1"		
BACCA		BA Mold Family	1/8" x 1/2"	1/8" x 1/2"		cUL, UL
BMCCGCG		BM Mold Family	1/8" x 1/2"	1/8" x 1/2"		
BBRCH		BB Mold Family	1/8" x 2"	1/8" x 2"		
ENDCHCH		EN Mold Family	1/8" x 2"	1/8" x 2"		
EPCCH		EP Mold Family	1/8" x 2"	1/8" x 2" and wider		UL, cUL
BMDCHCH		BM Mold Family	1/8" x 2"	1/8" x 2"		
EBCCHCH		EB Mold Family	1/8" x 2" and wider	1/8" x 2" and wider		
EPCK		EP Mold Family	1/8" x 3"	1/8" x 3" and wider		cUL, UL
ENKCMCM		EN Mold Family	1/8" x 4" and wider	1/8" x 4"		
EPDCM		EP Mold Family	1/8" x 4"	1/8" x 4" and wider		cUL, UL
BMKCMCM		BM Mold Family	1/8" x 4" and wider	1/8" x 4"		
BVJCMCM		BV Mold Family	1/8" x 4" and wider	1/8" x 4" and wider		
BACBAH		BA Mold Family	2 mm x 20 mm	2 mm x 20 mm		cUL, UL

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BACBAJ		BA Mold Family	2 mm x 25 mm	2 mm x 25 mm		UL, cUL
BMCBAJBAJ		BM Mold Family	2 mm x 25 mm	2 mm x 25 mm		
BMCBAKBAK		BM Mold Family	2 mm x 30 mm	2 mm x 30 mm	EN IEC® 62561-1 permanent connection	
BACBAK	222120	BA Mold Family	2 mm x 30 mm	2 mm x 30 mm	EN IEC® 62561-1 permanent connection	cUL, UL
BBCBAK	221640	BB Mold Family	2 mm x 30 mm	2 mm x 30 mm		
BBCCAF		BB Mold Family	3 mm x 10 mm	3 mm x 10 mm		
EBCCAFCAF		EB Mold Family	3 mm x 10 mm	3 mm x 10 mm		
EBCCAHCAL		EB Mold Family	3 mm x 20 mm	3 mm x 20 mm		
BHREAJCAL		BH Mold Family	4 mm x 25 mm	3 mm x 20 mm		
BBCCAHCAL		BB Mold Family	3 mm x 20 mm	3 mm x 20 mm		
BACCAJ		BA Mold Family	3 mm x 25 mm	3 mm x 25 mm		UL, cUL
BBCCAJ	221639	BB Mold Family	3 mm x 25 mm	3 mm x 25 mm		
EAKCAJCAL		EA Mold Family	3 mm x 25 mm	3 mm x 25 mm		
EBCCAJCAL		EB Mold Family	3 mm x 25 mm	3 mm x 25 mm		
EBCCAJEAL		EB Mold Family	3 mm x 25 mm	4 mm x 40 mm		
ENCCAJCAL		EN Mold Family	3 mm x 25 mm	3 mm x 25 mm		
TWRCAJ		TW Mold Family	3 mm x 25 mm	3 mm x 25 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMCPAMCAJ		BM Mold Family	6 mm x 50 mm	3 mm x 25 mm		
BMDCAJCAM		BM Mold Family	3 mm x 25 mm	3 mm x 50 mm		
BQCCAJCAJ		BQ Mold Family	3 mm x 25 mm	3 mm x 25 mm		
BGCCAJCAJ		BG Mold Family	3 mm x 25 mm	3 mm x 25 mm		
BGCCAMCAJ		BG Mold Family	3 mm x 50 mm	3 mm x 25 mm		
BJCCAJCAJ		BJ Mold Family	3 mm x 25 mm	3 mm x 25 mm		
BKCCAJCAJ		BK Mold Family	3 mm x 25 mm	3 mm x 25 mm		
BMCCAJCAJ	234426	BM Mold Family	3 mm x 25 mm	3 mm x 25 mm		
BMCCAJEAH		BM Mold Family	3 mm x 25 mm	4 mm x 20 mm		
BMCCAJEAL		BM Mold Family	3 mm x 25 mm	4 mm x 40 mm		
BMCCAMCAJ		BM Mold Family	3 mm x 50 mm and wider	3 mm x 25 mm		
BMCEAJCAJ		BM Mold Family	4 mm x 25 mm	3 mm x 25 mm		
BMCEAMCAJ		BM Mold Family	4 mm x 50 mm	3 mm x 25 mm		
EBCCA KCAK		EB Mold Family	3 mm x 30 mm	3 mm x 30 mm		
BBCCA K		BB Mold Family	3 mm x 30 mm	3 mm x 30 mm		
BACCAS		BA Mold Family	3 mm x 35 mm	3 mm x 35 mm		cUL, UL
EBCCASCAS		EB Mold Family	3 mm x 35 mm	3 mm x 35 mm		
EDRCASCAS		ED Mold Family	3 mm x 35 mm	3 mm x 35 mm and wider		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMCCASCAS		BM Mold Family	3 mm x 35 mm	3 mm x 35 mm		
BQCCASCAS		BQ Mold Family	3 mm x 35 mm	3 mm x 35 mm		
EBCCALCAL		EB Mold Family	3 mm x 40 mm	3 mm x 40 mm		
BMCEAMCAL		BM Mold Family	4 mm x 50 mm	3 mm x 40 mm		
BMDFANCAL		BM Mold Family	5 mm x 60 mm	3 mm x 40 mm		
BQCCALCAL		BQ Mold Family	3 mm x 40 mm	3 mm x 40 mm		
DERCALCAL		DE Mold Family	3 mm x 40 mm	3 mm x 40 mm		
BACCAL	223493	BA Mold Family	3 mm x 40 mm	3 mm x 40 mm		cUL, UL
BBCCAL	221645	BB Mold Family	3 mm x 40 mm	3 mm x 40 mm		
BBCFALCAL		BB Mold Family	5 mm x 40 mm	3 mm x 40 mm		
BJCCALCAL		BJ Mold Family	3 mm x 40 mm	3 mm x 40 mm		
BMCCALCAL		BM Mold Family	3 mm x 40 mm	3 mm x 40 mm		
BMCEAJCAL		BM Mold Family	4 mm x 25 mm	3 mm x 40 mm		
BBRCAM		BB Mold Family	3 mm x 50 mm	3 mm x 50 mm		
BGCCAMCAM		BG Mold Family	3 mm x 50 mm	3 mm x 50 mm		
BMCCAMEAJ		BM Mold Family	3 mm x 50 mm	4 mm x 25 mm		
BMDCAMCAM		BM Mold Family	3 mm x 50 mm	3 mm x 50 mm		
BQCCAMCAM		BQ Mold Family	3 mm x 50 mm	3 mm x 50 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
EBCCAMCAM		EB Mold Family	3 mm x 50 mm and wider	3 mm x 50 mm and wider		
BDEDG		BD Mold Family	3/16" x 1 1/2"	3/16" x 1 1/2"		
BJCDGDG		BJ Mold Family	3/16" x 1 1/2"	3/16" x 1 1/2"		
BMCDEDE		BM Mold Family	3/16" x 1"	3/16" x 1"		
BACDE		BA Mold Family	3/16" x 1"	3/16" x 1"		cUL, UL
ERJGHGH		ER Mold Family	3/8" x 2"	3/8" x 2"		UL, cUL
BKJGHGH		BK Mold Family	3/8" x 2"	3/8" x 2"		
BADGK		BA Mold Family	3/8" x 3"	3/8" x 3"		UL, cUL
EPDGM		EP Mold Family	3/8" x 4"	3/8" x 4" and wider		
BAKGN		BA Mold Family	3/8" x 5"	3/8" x 5"		
BAKGNM		BA Mold Family	3/8" x 5"	3/8" x 5"		
BBCDAK	221644	BB Mold Family	3.5 mm x 30 mm	3.5 mm x 30 mm		
BMCDAKDAK		BM Mold Family	3.5 mm x 30 mm	3.5 mm x 30 mm		
EBCDAKDAK		EB Mold Family	3.5 mm x 30 mm	3.5 mm x 30 mm		
EBCEAHEAH		EB Mold Family	4 mm x 20 mm	4 mm x 20 mm		
BMCEAHEAH		BM Mold Family	4 mm x 20 mm	4 mm x 20 mm		
BMCEAHEAL		BM Mold Family	4 mm x 20 mm	4 mm x 40 mm		
BMCEALEAH		BM Mold Family	4 mm x 40 mm	4 mm x 20 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BBREAMEAJ		BB Mold Family	4 mm x 50 mm	4 mm x 25 mm		
BMCEAJEAJ		BM Mold Family	4 mm x 25 mm	4 mm x 25 mm		
BMCEAKEAJ		BM Mold Family	4 mm x 30 mm	4 mm x 25 mm		
BACEAJ		BA Mold Family	4 mm x 25 mm	4 mm x 25 mm		cUL, UL
BACEAMEAJ		BA Mold Family	4 mm x 50 mm	4 mm x 25 mm		UL, cUL
BBCEAJ		BB Mold Family	4 mm x 25 mm	4 mm x 25 mm		
BMCEAMEAJ		BM Mold Family	4 mm x 50 mm	4 mm x 25 mm		
BMDEAJGAN		BM Mold Family	4 mm x 25 mm	8 mm x 60 mm		
BMKEAJGAP		BM Mold Family	4 mm x 25 mm	8 mm x 80 mm		
BQCEAJEAJ		BQ Mold Family	4 mm x 25 mm	4 mm x 25 mm		
BQCEAMEAJ		BQ Mold Family	4 mm x 50 mm	4 mm x 25 mm		
EAKEAJEAJ		EA Mold Family	4 mm x 25 mm	4 mm x 25 mm		
EBCEAJEAJ		EB Mold Family	4 mm x 25 mm	4 mm x 25 mm		
EBCEAKEAK		EB Mold Family	4 mm x 30 mm	4 mm x 30 mm		
EBCEALEAK		EB Mold Family	4 mm x 40 mm	4 mm x 30 mm		
EBCFALEAK		EB Mold Family	5 mm x 40 mm	4 mm x 30 mm		
BACEAK		BA Mold Family	4 mm x 30 mm	4 mm x 30 mm		UL, cUL
BBCEAK		BB Mold Family	4 mm x 30 mm	4 mm x 30 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMCEAKEAK		BM Mold Family	4 mm x 30 mm	4 mm x 30 mm		
BMCEAKFAL		BM Mold Family	4 mm x 30 mm	5 mm x 40 mm		
BQCEAKEAK		BQ Mold Family	4 mm x 30 mm	4 mm x 30 mm		
BMDEALFAM		BM Mold Family	4 mm x 40 mm	5 mm x 50 mm		
BMDEALGAN		BM Mold Family	4 mm x 40 mm	8 mm x 60 mm		
BQCEALEAL		BQ Mold Family	4 mm x 40 mm	4 mm x 40 mm		
BACEAL		BA Mold Family	4 mm x 40 mm	4 mm x 40 mm		cUL, UL
BBCEAL	222865	BB Mold Family	4 mm x 40 mm	4 mm x 40 mm		
EAKEALEAL		EA Mold Family	4 mm x 40 mm	4 mm x 40 mm		
EBCEALEAL		EB Mold Family	4 mm x 40 mm	4 mm x 40 mm		
EBCFANEAL		EB Mold Family	5 mm x 60 mm and wider	4 mm x 40 mm		
BKEEALAL		BK Mold Family	4 mm x 40 mm	4 mm x 40 mm		
BMCEALAL		BM Mold Family	4 mm x 40 mm	4 mm x 40 mm		
BMCEALFAL		BM Mold Family	4 mm x 40 mm	5 mm x 40 mm		
BMCEALPAK		BM Mold Family	4 mm x 40 mm	6 mm x 30 mm		
BBREAM		BB Mold Family	4 mm x 50 mm	4 mm x 50 mm		
BDEEAM		BD Mold Family	4 mm x 50 mm	4 mm x 50 mm		
BACEAM		BA Mold Family	4 mm x 50 mm	4 mm x 50 mm		cUL, UL

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMDEAMEAM	221697	BM Mold Family	4 mm x 50 mm	4 mm x 50 mm		
BMDFANEAM		BM Mold Family	5 mm x 60 mm	4 mm x 50 mm		
BQCEAMEAM		BQ Mold Family	4 mm x 50 mm and wider	4 mm x 50 mm		
EAKEAMEAM		EA Mold Family	4 mm x 50 mm	4 mm x 50 mm		
BQCFAHFAH		BQ Mold Family	5 mm x 20 mm	5 mm x 20 mm		
BACFAH	226996	BA Mold Family	5 mm x 20 mm	5 mm x 20 mm		UL, cUL
BBCFAK	221642	BB Mold Family	5 mm x 30 mm	5 mm x 30 mm		
BMCFAKFAK		BM Mold Family	5 mm x 30 mm	5 mm x 30 mm		
BCRFAKFAK	240324	BC Mold Family	5 mm x 30 mm	5 mm x 30 mm		
BKEFAKFAK		BK Mold Family	5 mm x 30 mm	5 mm x 30 mm		
EBCFAKFAK		EB Mold Family	5 mm x 30 mm	5 mm x 30 mm		
BMCFALFAL		BM Mold Family	5 mm x 40 mm	5 mm x 40 mm		
BMCFAMFAL		BM Mold Family	5 mm x 50 mm	5 mm x 40 mm		
BMDGAMFAL		BM Mold Family	8 mm x 50 mm	5 mm x 40 mm		
BMDPAMFAL		BM Mold Family	6 mm x 50 mm	5 mm x 40 mm		
BVEFALFAL		BV Mold Family	5 mm x 40 mm	5 mm x 40 mm		
BACFAL		BA Mold Family	5 mm x 40 mm	5 mm x 40 mm		cUL, UL
BBCFAL		BB Mold Family	5 mm x 40 mm	5 mm x 40 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BGCFALFAL		BG Mold Family	5 mm x 40 mm	5 mm x 40 mm		
BKEFALFAL		BK Mold Family	5 mm x 40 mm	5 mm x 40 mm		
EBCFALFAL	240363	EB Mold Family	5 mm x 40 mm and wider	5 mm x 40 mm and wider		
ECKFAMFAM		EC Mold Family	5 mm x 50 mm	5 mm x 50 mm		
EDFFAMFAM		ED Mold Family	5 mm x 50 mm	5 mm x 50 mm and wider		
BBRFAM	240358	BB Mold Family	5 mm x 50 mm	5 mm x 50 mm		
BCFFAMFAM		BC Mold Family	5 mm x 50 mm	5 mm x 50 mm		
BKEFAMPAM		BK Mold Family	5 mm x 50 mm	6 mm x 50 mm		
BKEPAMFAM		BK Mold Family	6 mm x 50 mm	5 mm x 50 mm		
BKJFAMGAN		BK Mold Family	5 mm x 50 mm	8 mm x 60 mm		
BMDFAMFAM		BM Mold Family	5 mm x 50 mm	5 mm x 50 mm		
BTJFAMFAM		BT Mold Family	5 mm x 50 mm	5 mm x 50 mm		
BVJFAMPAM		BV Mold Family	5 mm x 50 mm	6 mm x 50 mm		
BVJPAMFAM		BV Mold Family	6 mm x 50 mm and wider	5 mm x 50 mm		
BPDFAMGAM		BB Mold Family	5 mm x 50 mm	8 mm x 50 mm		
BMDFANFAN	240360	BM Mold Family	5 mm x 60 mm	5 mm x 60 mm		
BBKPAQ		BB Mold Family	6 mm x 100 mm	6 mm x 100 mm		
BBCPAJ		BB Mold Family	6 mm x 25 mm	6 mm x 25 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BMCPAJPAJ		BM Mold Family	6 mm x 25 mm	6 mm x 25 mm		
BMCPAKPAK		BM Mold Family	6 mm x 30 mm	6 mm x 30 mm		
EBCPAKPAK		EB Mold Family	6 mm x 30 mm	6 mm x 30 mm		
BBCPAK		BB Mold Family	6 mm x 30 mm	6 mm x 30 mm		
BACPAS		BA Mold Family	6 mm x 35 mm	6 mm x 35 mm		UL, cUL
BBCPAL	224831	BB Mold Family	6 mm x 40 mm	6 mm x 40 mm		
EAKPALPAL		EA Mold Family	6 mm x 40 mm	6 mm x 40 mm		
BMCPALPAL		BM Mold Family	6 mm x 40 mm	6 mm x 40 mm		
BCRPAL		BC Mold Family	6 mm x 40 mm	6 mm x 40 mm		
BJCPALPAL		BJ Mold Family	6 mm x 40 mm	6 mm x 40 mm		
EBCPALPAL		EB Mold Family	6 mm x 40 mm and wider	6 mm x 40 mm and wider		
EAKPAMPAM		EA Mold Family	6 mm x 50 mm	6 mm x 50 mm		
ENDPAMPAM		EN Mold Family	6 mm x 50 mm	6 mm x 50 mm		
BKJPAMPAM		BK Mold Family	6 mm x 50 mm	6 mm x 50 mm		
BACPAM		BA Mold Family	6 mm x 50 mm	6 mm x 50 mm		cUL, UL
BBDPAMGAN		BB Mold Family	6 mm x 50 mm	8 mm x 60 mm		
BBDPAMPAM		BB Mold Family	6 mm x 50 mm	6 mm x 50 mm		
BMDPAMPAM	226443	BM Mold Family	6 mm x 50 mm	6 mm x 50 mm		

CatalogNumber	Article Number	Mold Family	Lug/Busbar Size 1	Lug/Busbar Size 2	Complies With	Certifications
BQDPAMPAM		BQ Mold Family	6 mm x 50 mm and wider	6 mm x 50 mm		
BMDPANGAN		BM Mold Family	6 mm x 60 mm and wider	8 mm x 60 mm		
BMKGAQGAQ		BM Mold Family	8 mm x 100 mm and wider	8 mm x 100 mm		
BBKGAQ		BB Mold Family	8 mm x 100 mm	8 mm x 100 mm		
BBDGANGAN		BB Mold Family	8 mm x 60 mm	8 mm x 60 mm		
EAKGANGAN		EA Mold Family	8 mm x 60 mm	8 mm x 60 mm		
TWR107A3		TW Mold Family	26GA x 2"	26GA x 2"		

ADDITIONAL PRODUCT DETAILS

For applications such as computer room, tunnel or other low-ventilation areas, specify a smokeless nVent ERICO Cadweld Exolon mold. Add an XL prefix to the standard mold part number when ordering (for example, a TAC2Q2Q becomes XLTAC2Q2Q). Similarly, nVent ERICO Cadweld Exolon welding material is also designated by the XL prefix (for example, 150 becomes XL150).

A gap between conductors may be required. See mold tag for more information.

XX-X-XX-XX-L-M-W		
XX	Mold Family	
X	Price Key	
XX	Lug/Busbar Size 1	
XX	Lug/Busbar Size 2	
L*	Split Crucible	Crucible section is split on molds designed with horizontal opening for easier cleaning
M*	Mold Only	
W*	Wear Plates	Reduce mechanical abrasion of molds at cable entry points

* Empty if none

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE