

Theft-Deterrent Grounding Busbar, Post Mount Assembly

Data Solutions



CERTIFICATIONS



FEATURES

Mounts to a Schedule 40 pipe or post without cutting or drilling the pipe

Accepts standard telecommunication grounding lugs (lugs not included)

Includes 14 Standard Spacers (TDSGAS)

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Finish	Spacer Thickness	Length (L)	A	Fence Post Size, Nominal
----------------	----------	--------	------------------	------------	---	--------------------------

TDSGAPC14	Copper, Stainless Steel 304 (EN 1.4301), Stainless Steel 18-8 (EN 1.4305), Nylon	Tinned	6.4mm	266mm	25.4mm	1.5 – 2in
-----------	--	--------	-------	-------	--------	-----------

Table 2/2				
Catalog Number	Fence Post Outside Diameter, Actual (Ø)	Thread Size 1 (TS1)	Thread Size 2 (TS2)	Thread Size 3 (TS3)
TDSGAPC14	48 – 63.5mm	3/8" UNC	5/16" UNC	5/16" UNC

DIAGRAMS

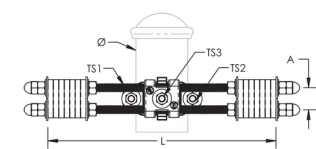

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE