

Stamped U-Bolt Pipe Clamp



CERTIFICATIONS



FEATURES

Clamp for bonding of pipes and exhaust stacks to the lightning protection system

Listed to UL® 96

SPECIFICATIONS


Table 1/2

Catalog Number	Material	Outer Diameter (OD)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPA5966	Aluminum, Stainless Steel 304 (EN 1.4301)	111.1 - 174.2 mm	50.8mm	223.84 mm	211.15 mm	0.34 kg
LPA5964	Aluminum, Stainless Steel 304 (EN 1.4301)	99.1 - 107.97 mm	50.8mm	147.64 mm	158.75 mm	0.34 kg
LPC5966	Copper, Stainless Steel 304 (EN 1.4301)	111.1 - 174.2 mm	50.8mm	223.84 mm	211.15 mm	0.37 kg

CatalogNumber	Material	Outer Diameter (OD)	Depth (D)	Height (H)	Width (W)	Unit Weight
LPC5964	Copper, Stainless Steel 304 (EN 1.4301)	99.1 - 117.47 mm	50.8mm	147.64 mm	158.75 mm	0.4 kg

Table 2/2	
Catalog Number	Certifications
LPA5966	E202878-Combined_CoC, E202878-Combined_CoC
LPA5964	E202878-Combined_CoC, E202878-Combined_CoC
LPC5966	
LPC5964	E202878-Combined_CoC, E202878-Combined_CoC

DIAGRAMS

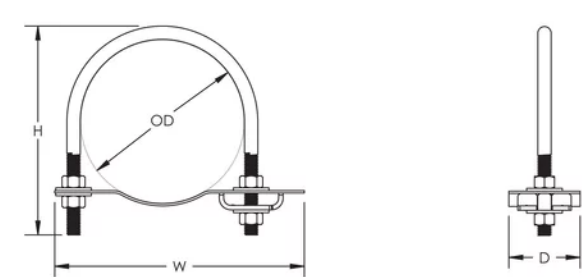

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE