


# Varistar CP Steel Door, Perforated With 3-Point Electronic Locking

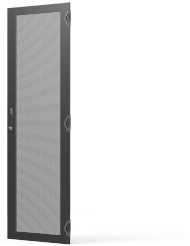

Varistar CP perforated steel door 3-point locking for IP 20 applications.

## FEATURES

Perforated steel door with 3-point locking for IP 20 protection class

Lever handle with built-in push button

Opening angle 180°

## SPECIFICATIONS

- Locking Type:** 3-Point Locking, Electronic
- Product Type:** Cabinet Door
- Protection Rating:** IP20
- Material:** Steel

Table 1/2

Catalog Number	Rack Height	Height	Width	Type	Package Quantity	Color
21630-814	42U	2000mm	600mm	Steel Door, Perforated, Hinged, Left	1	Black Grey
21630-815	47U	2200mm	600mm	Steel Door, Perforated, Hinged, Left	1	Black Grey
21630-816	52U	2450mm	600mm	Steel Door, Perforated, Hinged, Left	1	Black Grey

CatalogNumber	Rack Height	Height	Width	Type	Package Quantity	Color
21630-817	42U	2000mm	800mm	Steel Door, Perforated, Hinged, Left	1	Black Grey
21630-818	47U	2200mm	800mm	Steel Door, Perforated, Hinged, Left	1	Black Grey
21630-819	52U	2450mm	800mm	Steel Door, Perforated, Hinged, Left	1	Black Grey
21630-895	42U	2000mm	600mm	Steel Door, Perforated, Hinged, Right	1	Black Grey
21630-896	47U	2200mm	600mm	Steel Door, Perforated, Hinged, Right	1	Black Grey
21630-897	52U	2450mm	600mm	Steel Door, Perforated, Hinged, Right	1	Black Grey
21630-898	42U	2000mm	800mm	Steel Door, Perforated, Hinged, Right	1	Black Grey
21630-899	42U	2000mm	800mm	Steel Door, Perforated, Hinged, Right	1	Black Grey
21630-900	52U	2450mm	800mm	Steel Door, Perforated, Hinged, Right	1	Black Grey

Table 2/2

Catalog Number	Color Code	Complies With	Finish	Works With	Quick Ship
21630-814	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-815	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-816	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-817	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-818	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No

Catalog Number	Color Code	Complies With	Finish	Works With	Quick Ship
21630-819	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-895	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-896	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-897	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-898	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-899	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No
21630-900	RAL 7021	IEC 61587-1	Powder Coated	Varistar CP	No

## ADDITIONAL PRODUCT DETAILS

Please order DIN profile half cylinder for lever handle separately.

Please purchase the grounding kit separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**