

BC-M Conduit to Beam Clamp



CERTIFICATIONS



FEATURES

Easy installation to beam flanges

Eliminates offset bending conduit

Conduit clip rotates 360 degrees

SPECIFICATIONS

Finish: nVent CADDY Armour


Material: Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load	Certifications
EBC6M	172580	14 - 18 mm	16 mm Max	3 N·m	450N	
EBC812M	160200	18 - 30 mm	16 mm Max	3 N·m	450N	ITB
EBC16M	172590	23.4 - 35 mm	16 mm Max	3 N·m	450N	ITB

CatalogNumber	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Torque (TQ)	Static Load	Certifications
EBC20M	172600	35 - 42 mm	16 mm Max	3 N·m	450N	ITB
EBC24M	172610	42 - 50 mm	16 mm Max	3 N·m	450N	ITB
EBC32M	172620	50 - 60 mm	16 mm Max	3 N·m	450N	ITB

DIAGRAMS

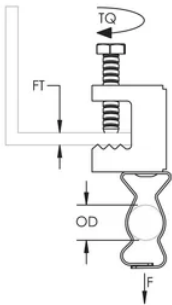

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

