

nVent CADDY Speed Link SLDM with Hook



CERTIFICATIONS



FEATURES

Complete system includes wire, locking device and pre-assembled hook end fitting

Ideal for supporting lighting, ductwork and other installation projects

Sleek, low-profile locking device reduces visual impact

Keyless locking device is adjustable even after installation

SPECIFICATIONS

- Wire Rope Diameter:** 1.5 mm
- Static Load Safety Factor:** 5:1
- Finish:** Electrogalvanized
- Material:** Steel


Table 1/1

| Catalog Number | Article Number | Wire Rope Length | A | B | C | Static Load |
|----------------|----------------|------------------|---------|---------|--------|-------------|
| SLDM615L2 | 196029 | 2m | 58.4 mm | 22.9 mm | 6.4 mm | 195N |

| CatalogNumber | Article Number | Wire Rope Length | A | B | C | Static Load |
|---------------|----------------|------------------|---------|---------|--------|-------------|
| SLDM615L1 | 196028 | 1m | 58.4 mm | 22.9 mm | 6.4 mm | 195N |

Rod Size (RS): 6
Length (L): 7mm
Width (W): 9.2 mm
Height (H): 24.5 mm

DIAGRAMS

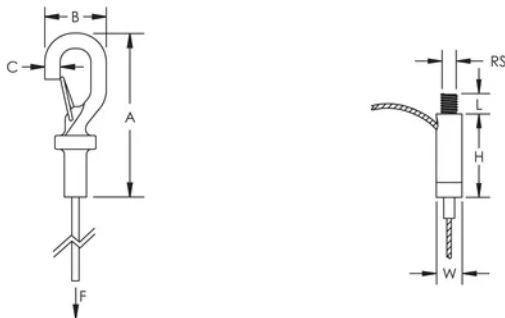

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical
 Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

