

# PEMSA Wire Basket Tray Light Duty Ceiling Support



## CERTIFICATIONS



## FEATURES

Ideal for tray widths up to 150mm

Side load access for cable installation

Fast and secure quick click installation features

IEC 61537 load rating and earthing compliant

## SPECIFICATIONS

Table 1/2


| Catalog Number | Article Number | Material | Finish            | Length 1 (L1) | Length 2 (L2) | Width (W) |
|----------------|----------------|----------|-------------------|---------------|---------------|-----------|
| WBT60COHBRKT   | 820300         | Steel    | Electrogalvanized | 80 mm         | 55.2 mm       | 45 mm     |

Table 2/2

| Catalog Number | Article Number | Height (H) | Hole Size (HS) | Static Load |
|----------------|----------------|------------|----------------|-------------|
|----------------|----------------|------------|----------------|-------------|

|              |        |        |       |      |
|--------------|--------|--------|-------|------|
| WBT60COHBRKT | 820300 | 152 mm | 11 mm | 147N |
|--------------|--------|--------|-------|------|

### DIAGRAMS

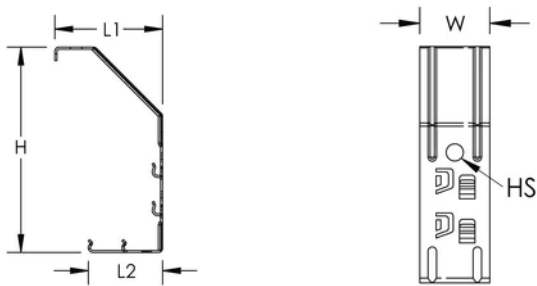

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical Support

#### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

#### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

#### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

