 


PFF Parallel Plastic Screw-In Plug for P13/P14 Couplers, European Design



The European Design Version (Suffix EE) is currently being phased out. All future projects should be designed with the Worldwide Design Version (Suffixes N and LN). This change is being done in order to simplify our product offering and eliminate redundant designs. Please contact Customer Care or your local Sales Engineer/Manager if you require more information on this transition.

FEATURES

Designed for use with the P13/P14 coupler families

Designed to keep dirt, water and concrete slurry out of the coupler during the concrete pour

Durable mounting plates allow for easy attachment to forms

Color coded for the appropriate coupler size

SPECIFICATIONS

Design Version: European (Specialty Materials)

Material: High Density Polyethylene (HDPE);Steel

Table 1/2


Catalog Number	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL1416PFF	153810	14 mm, 16 mm	#5	15M	65 mm	15 mm
EL1012PFF	153800	10 mm, 12 mm	#3, #4	10M	65 mm	15 mm
EL2225PFF	153840	22 mm, 25 mm	#7, #8	25M	95 mm	18 mm
EL2830PFF	153850	28 mm, 30 mm	#9	30M	95 mm	18 mm

CatalogNumber	Article Number	Rebar Size, Metric	Rebar Size, US	Rebar Size, Canada	Diameter (Ø)	Height (H)
EL20PFF	153830	20 mm	#6	20M	75 mm	18 mm
EL18PFF	153820	18 mm			75 mm	18 mm
EL32PFF	153860	32 mm	#10		95 mm	18 mm
EL40PFF	153870	40 mm			95 mm	18 mm

Table 2/2

Catalog Number	Article Number	Color
EL1416PFF	153810	Black
EL1012PFF	153800	Red
EL2225PFF	153840	Red
EL2830PFF	153850	Black
EL20PFF	153830	Yellow
EL18PFF	153820	White
EL32PFF	153860	Yellow
EL40PFF	153870	Green

DIAGRAMS

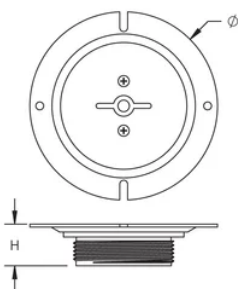

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE