


# Front Panel, Front anodized, Rear Conductive, Unshielded, 3 U, 84 HP

## Power Utilities

### CATALOG NUMBER

**30838-123**

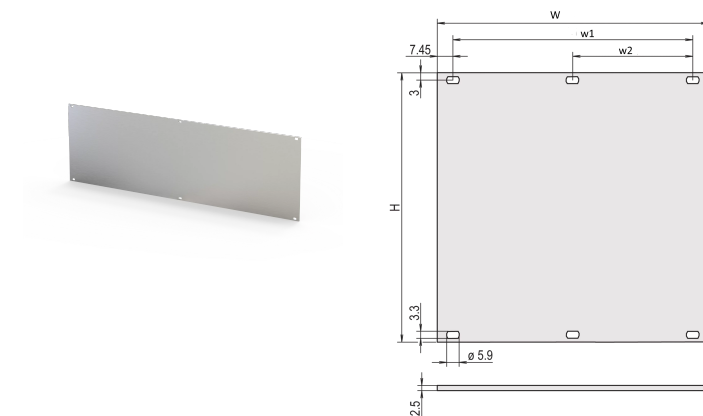

Front panel, unshielded, front anodized and rear conductive.

### CERTIFICATIONS



### FEATURES

Partial width front panel, Al, 2.5 mm

Al, front anodized, conductive

### PRODUCT ATTRIBUTES

Product Type: Front Panel

Type: Front Panel without Handle

Handle Type: None

Mounting: Screw-on Front

EMC Shielding: No

Material: Aluminum

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: No

Rack Height: 3 U

Height: 128.4 mm

Rack Width: 84 HP

Width: 426.4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Please order fixing material (sleeves, collar screws) separately.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**