


# Fan Control Module FCM2

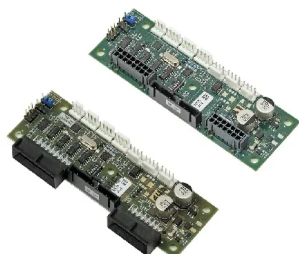

Management Module for Fan Control and Voltage Monitoring.

## CERTIFICATIONS



## FEATURES

The fan control module (FCM2) is a standalone fan controller for 12 V fans

Up to 6 fans can be monitored and controlled

Signal monitoring of up to 6 temperature sensors

Monitoring of 3.3 V, 5 V, 12 V and -12 V voltages

FCM2 supply voltage: 12 V

Can control status LEDs for Over Temp, Fan Fail, 3.3 V, 5 V, 12 V and -12 V

In case of overheating or the failure of a fan, the other fans can be set to full speed

Status information can be queried via I<sup>2</sup>C interface

Suitable for a 4 wire fan with PWM or control voltage input

## SPECIFICATIONS

Table 1/1

| Catalog Number | Works With         | Depth | Height | Width | Package Quantity | Quick Ship |
|----------------|--------------------|-------|--------|-------|------------------|------------|
| 23207-160      | CompactPCI Systems | 119mm | 15mm   | 40mm  | 1                | No         |

| CatalogNumber | Works With         | Depth | Height | Width | Package Quantity | Quick Ship |
|---------------|--------------------|-------|--------|-------|------------------|------------|
| 23207-162     | CompactPCI Systems | 119mm | 15mm   | 40mm  | 1                | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**