

4G24H Twist Clip with 90° Plain Hole



CERTIFICATIONS



FEATURES

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from T-Grid

Fast, easy and secure twist-on installation

Designed to reduce scratching of T-grid

No tools required for installation

SPECIFICATIONS

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)	T-Grid Size
4G24H	170490	nVent CADDY Armour	Gray	5.8 mm	1.5 mm Max	24mm
4G24HWHSP25	172280	Painted	White	5.8 mm	1.5 mm Max	24mm

CatalogNumber	Article Number	Finish	Color	Hole Size (HS)	Flange Thickness (FT)	T-Grid Size
4G24HWH	170500	Painted	White	5.8 mm	1.5 mm Max	24mm

Table 2/2

Catalog Number	Article Number	Static Load
4G24H	170490	180N
4G24HWHSP25	172280	180N
4G24HWH	170500	180N

DIAGRAMS

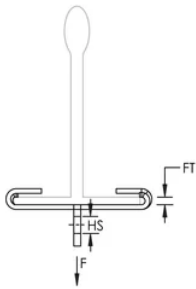

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

