



# Rebar Grounding Clamp, Heavy Duty

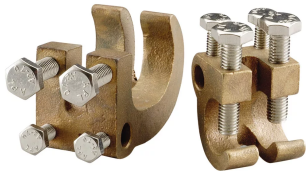

## CERTIFICATIONS

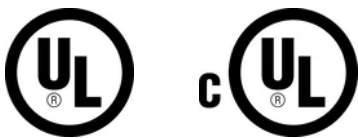

## FEATURES

Provides two connection points to concrete encased electrodes (rebar) for states where the Authority Having Jurisdiction (AHJ) requires it

Meets 2005 NEC® standard requirement for bonding to rebar into the grounding system

Suitable for direct burial applications

Has high-strength bronze alloy construction

Easy to install

## SPECIFICATIONS


**Material:** Bronze

Table 1/1

| Catalog Number | Article Number | Conductor Size                                                                              | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Certifications |
|----------------|----------------|---------------------------------------------------------------------------------------------|--------------------|----------------|--------------------|----------------|
| RC70           | 710325         | #8 Solid - 2/0<br>Stranded, 10 mm <sup>2</sup><br>Stranded - 70 mm <sup>2</sup><br>Stranded | 8 - 18 mm          | #3 - #6        | 10M - 20M          | UL             |

| CatalogNumber | Article Number | Conductor Size                                                          | Rebar Size, Metric | Rebar Size, US | Rebar Size, Canada | Certifications |
|---------------|----------------|-------------------------------------------------------------------------|--------------------|----------------|--------------------|----------------|
| RC100         | 710335         | #8 Solid - 4/0<br>Stranded, 10<br>mm² Stranded -<br>100 mm²<br>Stranded | 18 - 36 mm         | #6 – #11       | 20M – 35M          | UL, cUL        |

## DIAGRAMS

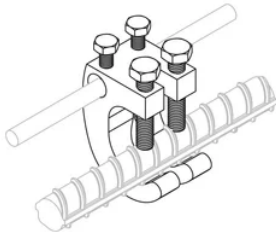

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including lead, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**