


# Plug-In Unit Kit for FMC, Chromated, Shielded (Textile) With Handle

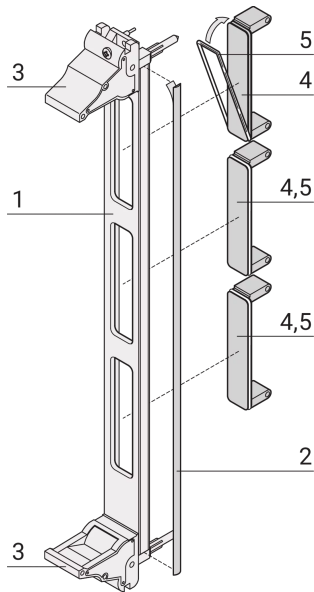

The FMC bezel are in accordance with Vita 57.1 specification. Covers the cut out in the overall front panel.

## CERTIFICATIONS



## FEATURES

In accordance with Vita 57.1 specification

For single 69.0 x 76.5 mm or double 139.0 x 76.5 mm modules

AI-Profile plug-in unit with IEL handle

## SPECIFICATIONS

|                      |                      |
|----------------------|----------------------|
| <b>Rack Width:</b>   | 4HP                  |
| <b>Material:</b>     | Aluminum             |
| <b>Finish:</b>       | Anodized; Passivated |
| <b>Product Type:</b> | Front Panel          |

**Type:** Front Panel with Handle (PIU)

**EMC Shielding:** Yes

Table 1/2

| Catalog Number | Rack Height | Package Quantity | Handle Type | Mounting       | EMC Gasket Type | Front Finish |
|----------------|-------------|------------------|-------------|----------------|-----------------|--------------|
| 20836-253      | 3U          | 1                | IEL         | Screw-on Front | Textile         | Anodized     |
| 20836-254      | 6U          | 1                | IEL         | Screw-on Front | Textile         | Anodized     |

Table 2/2

| Catalog Number | Rear Finish | Treated Edges | Complies With                  | Height  | Width | Quick Ship |
|----------------|-------------|---------------|--------------------------------|---------|-------|------------|
| 20836-253      | Conductive  | No            | FMC<br>Mezzanine, Vita<br>57.1 | 128.4mm | 20mm  | No         |
| 20836-254      | Conductive  | No            | FMC<br>Mezzanine, Vita<br>57.1 | 261.8mm | 20mm  | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**