


# EM-MR Conduit to Flange Clip with Retainer

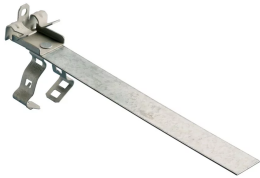

## FEATURES

Only one piece to install

Fast hammer-on installation

Pre-riveted retainer strap is easily bent into position

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Material:** Spring Steel

Table 1/1

Catalog Number	Outer Diameter	Flange Thickness	Static Load
CM2416M	23.4 - 35 mm	3.2 - 6.4 mm	330N
CM24812M	18 - 30 mm	3.2 - 6.4 mm	330N
CM5816M	23.4 - 35 mm	7.9 - 12.7 mm	330N
CM58812M	18 - 30 mm	7.9 - 12.7 mm	330N
CM912812M	18 - 30 mm	14.3 - 19.1 mm	330N
CM91216M	23.4 - 35 mm	14.3 - 19.1 mm	330N

**WARNING**

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

