

# H-PSM Conduit to Flange Clip, Side Mount



## FEATURES

Requires only a hammer to install

Available for EMT, rigid and aluminum conduit

Will pivot thru 360°

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Orientation:** Side Mount


**Material:** Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)
12P24SM	175220	22 - 30 mm	3 - 8 mm	111N
16P24SM	175260	30 - 35 mm	3 - 8 mm	111N
8P24SM	175180	18 - 22 mm	3 - 8 mm	111N
12P58SM	175230	22 - 30 mm	8 - 14 mm	111N
16P58SM	175270	30 - 35 mm	8 - 14 mm	111N

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)
8P58SM	175190	18 - 22 mm	8 - 14 mm	111N
8P912SM	175200	18 - 22 mm	14 - 20 mm	111N
12P912SM	175240	22 - 30 mm	14 - 20 mm	111N
16P912SM	175280	30 - 35 mm	14 - 20 mm	111N

## DIAGRAMS

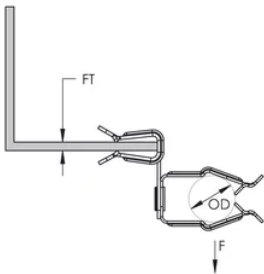

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

### Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

### Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

### APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**

