

# Hammer-On Flange Clip, Bottom Mount with Stud



## CERTIFICATIONS



## FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Captive threaded stud minimizes the need for additional hardware

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Material:** Spring Steel


Table 1/2

Catalog Number	Flange Thickness (FT)	Rod Size (RS)	Screw Diameter (Sc)	Screw Length (L)	Static Load 1 (F1)	Static Load 2 (F2)
M24S	3 - 8 mm	0.25	0.25	9.5mm	440N	330N

CatalogNumber	Flange Thickness (FT)	Rod Size (RS)	ScrewDiameter (Sc)	Screw Length (L)	Static Load 1 (F1)	Static Load 2 (F2)
M58S	8 - 14 mm	0.25	0.25	9.5mm	440N	330N
M912S	14 - 20 mm	0.25	0.25	9.5mm	440N	330N

Table 2/2	
Catalog Number	Static Load 3 (F3)
M24S	110N
M58S	110N
M912S	110N

### DIAGRAMS

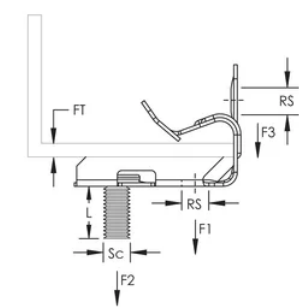

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

