

INC8 Internal Strut Beam Clamp



FEATURES

Mounts strut within beams

SPECIFICATIONS

Table 1/2

Catalog Number	Material	Finish	Strut Type	A	Screw Diameter (Sc)	Screw Length (L)
INC8T5	Spring Steel	nVent CADDY Armour	A (41 x 41 mm), C (21 x 41 mm)	13 mm	0.3125	25.4mm


Table 2/2

Catalog Number	Torque (TQ)	Static Load
INC8T5	7 N·m	440N

ADDITIONAL PRODUCT DETAILS

Strut channel must be cut 3/4" (20mm) shorter than the inner distance between the two beam flanges in order to accommodate the clamps.

DIAGRAMS

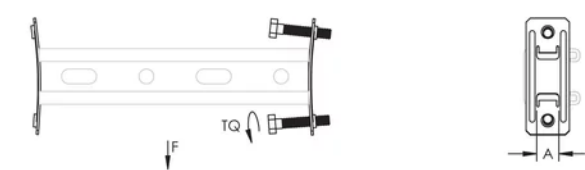

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

