

nVent CADDY Pyramid RL Adjustable Roller Support



FEATURES

Height-adjustable roller-based support designed specifically for rooftop applications

Height adjustability allows for effective navigation of pipe around obstructions

Polymeric rollers ensure corrosion free rotation

Foam bottom offers low abrasion interface for better roof membrane protection

Compatible with roof surfaces including single ply, bituminous, metal and spray foam

Ready to use out of the box, saving installation time and labor

Hot-dip galvanized and UV stabilized for long lasting performance

SPECIFICATIONS

Static Load Safety Factor:	3:1
Finish:	Hot-Dip Galvanized
Material:	Polyethylene;Polypropylene;Steel
Temperature:	-45 to 65 °C


Table 1/2

Catalog Number	Article Number	NB/DN	Height (H)	Length (L)	Width (W)	A
PRA6H16	360474	150 Max	165 - 406 mm	483mm	203 mm	260 mm
PRA3H12	360473	80 Max	152 - 305 mm	317.5mm	203 mm	159 mm

Table 2/2

Catalog Number	Article Number	Surface Area	Unit Weight	Static Load
PRA6H16	360474	91613mm ²	2 kg	2670N
PRA3H12	360473	59355mm ²	2 kg	1112N

DIAGRAMS

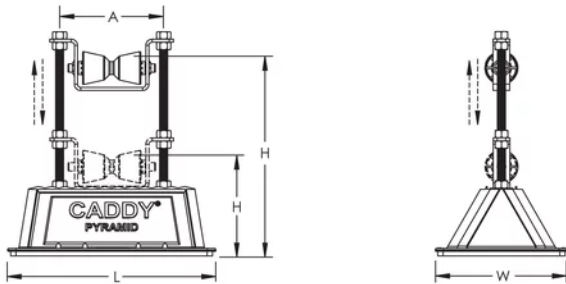

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

