

# nVent CADDY Speed Link SLS with Wedge Anchor



## CERTIFICATIONS



## FEATURES

Complete system includes wire, locking device and wedge anchor from Powers Fasteners, Inc.

Quickly and easily attaches into cracked and non-cracked concrete

Installs in strut profiles without the need to insert fingers or tools into the strut

Finger tightening of nut secures the locking device into position without tools

No special tools required

ETA-13/0355 assessment available for wedge anchor from Powers Fasteners, Inc

## SPECIFICATIONS

|                                   |                                |
|-----------------------------------|--------------------------------|
| <b>Wire Rope Diameter:</b>        | 2 mm                           |
| <b>Static Load Safety Factor:</b> | 5:1                            |
| <b>Finish:</b>                    | Electrogalvanized              |
| <b>Material:</b>                  | Steel;Polypropylene;Zinc Alloy |
| <b>Complies With:</b>             | SMACNA HVAC-DCS                |

Table 1/2

| Catalog Number | Article Number | Wire Rope Length | Length (L) | Drill Bit Diameter | Drill Hole Depth | Embedment Depth |
|----------------|----------------|------------------|------------|--------------------|------------------|-----------------|
| SLS2L5WA6      | 196760         | 5m               | 63.5mm     | 6mm                | 60mm             | 55 mm Min       |
| SLS2L3WA6      | 196759         | 3m               | 63.5mm     | 6mm                | 60mm             | 55 mm Min       |

Table 2/2

| Catalog Number | Article Number | Static Load |
|----------------|----------------|-------------|
| SLS2L5WA6      | 196760         | 270N        |
| SLS2L3WA6      | 196759         | 270N        |

**Slot Size (SS):** 8 x 6.5 mm - 8 x 10 mm

**Hole Size (HS):** 8 - 10 mm

**Width (W):** 16 mm

**Height 2 (H2):** 43.5mm

**Height 1 (H1):** 53mm

**Thread Size (TS):** M8


**Thickness (T):** 4 mm Max

## ADDITIONAL PRODUCT DETAILS

The 2 mm locking device is compatible with C-Channel Types E0 and E0L.

Total load per wire on a multi-tier trapeze must not exceed static load.

## DIAGRAMS

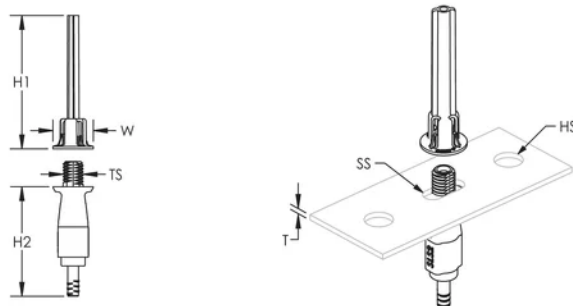

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

