


# Disk

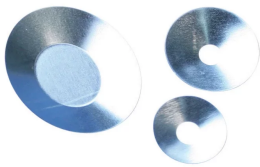

## FEATURES

Required each time a traditional nVent ERICO Cadweld connection is made

Placed at the bottom of the crucible, holding the welding material until the reaction takes place

## SPECIFICATIONS

**Material:** Steel

Table 1/1

Catalog Number	Welding Material	Diameter
B117A100	15 - 32, Sold Separately	19.05 mm
B117B50	45 - 115, Sold Separately	25.4 mm
B117C50	150 - 500, Sold Separately	38.1 mm

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

**Europe**

Netherlands:

+31 800-0200135

France:

+33 800 901 793

**Europe**

Germany:

800 1890272

Other Countries:

+31 13 5835404

**APAC**

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**