


Pagoda Tops, fits 800x400mm, Painted

CATALOG NUMBER

PPT84

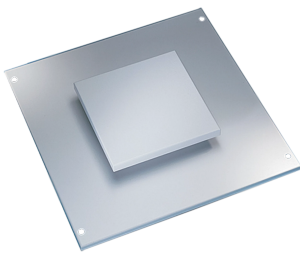

Pagoda Tops are available to fit on standard frames. Design features a drip-proof raised pagoda vent with a 115-volt integral axial exhaust fan. Double-bay Pagoda Tops have one drip-proof raised pagoda vent opening positioned over one bay that can be oriented for right or left ventilation.

INDUSTRY STANDARDS

This component is rated UL Type 1. Installing this component on an enclosure brings the enclosure rating to UL Type 1.

FEATURES

Bolts secure pagoda top to frame (lifting eyes can be used instead of bolts).

Drip-protected vent

PRODUCT ATTRIBUTES

Article Number: 20309

Material: Mild Steel

Fits Frame Top: 800 x 400mm

Frame Type: Single-Bay

Color: Light Gray

Color Code: RAL 7035

Finish: Powder Coated

Thickness: 1.9mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE