


# ProLine Containment System Express Rack Top Baffles

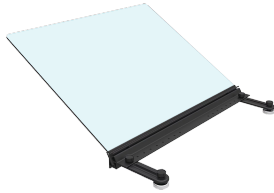

The Rack Top Baffles are suitable for most standard width cabinets with solid, perforated or semi-solid steel tops. The baffles will not work with aluminum framed cabinets or open framed racks.

## FEATURES

Allows additional natural light into aisle

The Rack Top Baffles require a minimum of 1 inch (25 mm) unobstructed depth across the entire front edge of the cabinet for secure attachment

Additionally, the two attachment fixtures on each baffle require a 1.50 x 5.50 inch (38 x 140 mm) unobstructed area on the top of the cabinet

These attachment mounts allow a high degree of flexibility across the top of the cabinet to work around obstructions

Prevents hot exhaust air from wrapping over the tops of racks

Attaches to top of rack magnetically

Angular baffle designed for cold aisle application

Vertical baffle is designed for hot aisle application

Reconfigurable design allows angular or vertical configuration

Tool-less Ceiling Panels are easy to install and remove for cleaning and provide above-the-cabinet access to cables, equipment and systems

Clear, transparent door and roof panels provide maximum light to aisleway

Express containment system includes magnetic mounting for quick-install

Express containment top baffles include both hot and cold aisle configurations

SPECIFICATIONS

**Color:** Jet Black  
**Finish:** Powder Coated  
**Material:** PVC  
**Color Code:** RAL 9005

| Table 1/1      |                |        |       |       |            |
|----------------|----------------|--------|-------|-------|------------|
| Catalog Number | Article Number | Height | Width | Depth | Quick Ship |
| UACTB7A        | 38611          | 277mm  | 697mm | 572mm | No         |
| UACTB6A        | 38607          | 277mm  | 599mm | 572mm | No         |
| UACTB6V        | 38608          | 277mm  | 599mm | 572mm | No         |
| UACTB75A       | 38613          | 277mm  | 749mm | 572mm | No         |
| UACTB75V       | 38614          | 277mm  | 749mm | 572mm | No         |
| UACTB7V        | 38612          | 277mm  | 697mm | 572mm | No         |
| UACTB8A        | 38615          | 277mm  | 794mm | 572mm | No         |
| UACTB8V        | 38616          | 277mm  | 794mm | 572mm | No         |

ADDITIONAL PRODUCT DETAILS

Custom sizes are available

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**