


# Rack Angles 23-inch

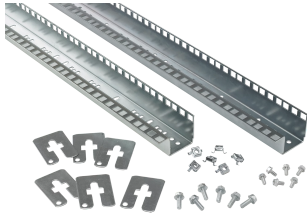

23-in. Rack Angles are available for telecom applications. They fit directly into 700-mm wide frames or into 800-mm wide frames using frame reducing brackets. Rack Angles have 10-32 tapped holes. 23-inch Rack Angles are available with 1.00-inch vertical hole spacing.

## FEATURES

---

Furnished in pairs

Tapped-Hole Rack Angles are constructed from 12 gauge conductive steel

Rack Angles have 10-32 tapped holes

Rack Angles fit directly into 700-mm wide frames, or 800-mm wide frames using frame reducing brackets (sold separately)

SPECIFICATIONS

Finish: Plated

| Table 1/1      |                |            |            |        |           |           |
|----------------|----------------|------------|------------|--------|-----------|-----------|
| Catalog Number | Article Number | Material   | Rack Units | Length | Hole Type | Thickness |
| PRA2318TP      | 65160          | Mild Steel | 38U        | 1676mm | Tapped    | 2.66mm    |
| PRA2314TP      | 65140          | Mild Steel | 29U        | 1270mm | Tapped    | 2.66mm    |
| PRA2320TP      | 65170          | Mild Steel | 42U        | 1879mm | Tapped    | 2.66mm    |
| PRA237TP       | 65130          | Mild Steel | 13U        | 584mm  | Tapped    | 2.66mm    |
| PRA2316TP      | 65150          | Mild Steel | 33U        | 1473mm | Tapped    | 2.66mm    |

ADDITIONAL PRODUCT DETAILS

Vertical holes spaced in 1.00 in. (25.4mm) increments.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE