

# Tip Receptor Mount

## Power Utilities



### FEATURES

Improved performance at tip of blade

Performance tested beyond IEC® 61400-24

Superior receptor product life performance


Less than 12 °C (54 °F) temperature rise after strike of 225 kA

### SPECIFICATIONS

Table 1/1

| Catalog Number | Height (H) | Width (W) | A      |
|----------------|------------|-----------|--------|
| WT2TC1MV05.5   | 40 mm      | 106 mm    | 130 mm |

### DIAGRAMS

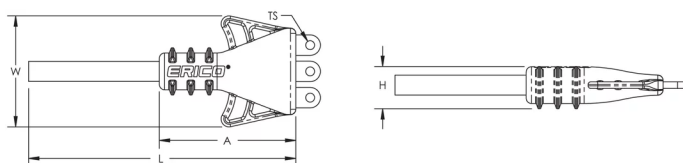

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**