


# Novastar Door Hinge Bracket for Shortened Door

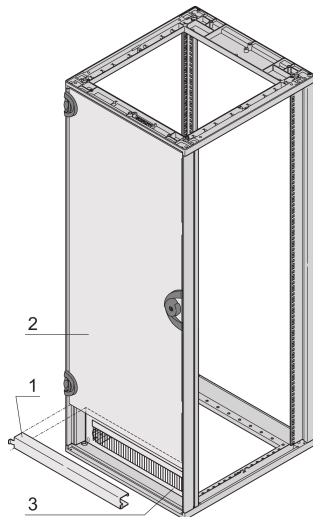

Door Hinge Bracket for shortened Doors, Heavy-Duty and Slim-Line, Front or Rear.

## CERTIFICATIONS



## FEATURES

Mounting (1 U assembly space required) can be above or below the short door

For steel doors that do not run the full height of the cabinet

Requires 1 U installation space

The clearance can be covered by 19" front panels or a cable through-ducting plate (3 U or 4 U)

## SPECIFICATIONS

**Product Type:** Bracket

Table 1/2

| Catalog Number | Rack Height | Width | Material | Works With | Package Quantity | Color |
|----------------|-------------|-------|----------|------------|------------------|-------|
|----------------|-------------|-------|----------|------------|------------------|-------|

|           |    |       |       |         |   |            |
|-----------|----|-------|-------|---------|---|------------|
| 27230-060 | 1U | 553mm | Steel | Cabinet | 1 | Black Grey |
| 27230-061 | 1U | 553mm | Steel |         | 1 | Black Grey |
| 27230-098 |    | 553mm | Steel | Cabinet | 1 | Black Grey |

Table 2/2

| Catalog Number | Color Code | Finish        | Height  | Type               | Quick Ship |
|----------------|------------|---------------|---------|--------------------|------------|
| 27230-060      | RAL 7021   | Powder Coated | 44.45mm | Door Hinge Bracket | No         |
| 27230-061      | RAL 7021   | Powder Coated | 44.45mm | Door Hinge Bracket | No         |
| 27230-098      | RAL 7021   | Powder Coated | 44.45mm | Bracket            | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**