

VF-Ti/T Rod to C-Purlin Clip



CERTIFICATIONS



FEATURES

Hammer-on or install from the floor with the VAFT tool

Provides an attachment for nVent CADDY Speed Link assemblies, wire, S-hooks, or chain from purlin and bar joist

SPECIFICATIONS

Finish: nVent CADDY Armour


Table 1/2

Catalog Number	Article Number	Material	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Height (H)
VF146T		Spring Steel	9.5 mm	Plain	1.5 - 6 mm	132 mm
VF146TI		Spring Steel	0.375 mm	Threaded	1.5 - 6 mm	132 mm
VF14T10	179060	Steel	10 mm	Plain	1.5 - 6 mm	110 mm

Table 2/2

Catalog Number	Article Number	Static Load	Certifications
VF146T		700N	cUL, UL
VF146TI		700N	UL, cUL
VF14T10	179060	700N	

DIAGRAMS

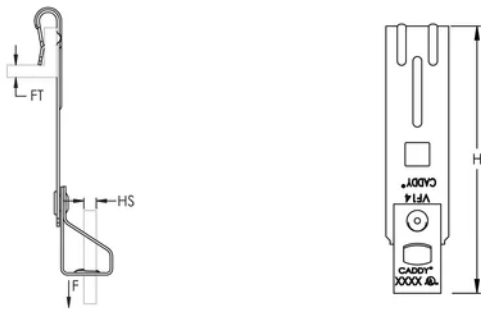

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

