


Cathodic Bonding Strap, 2 Holes, 254 mm x 31.75 mm

Data Solutions

CATALOG NUMBER

CAB496A32B0

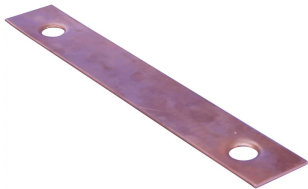

FEATURES

Allows electrical bonding across joints of steel pipe

Used to bond across standard mechanical joints or across "Dresser Type" joints when the coupling does not have to be bonded

Approximate electrical equivalent of a 1/0 conductor

Made of soft copper for easy forming

nVent ERICO Cadweld connections to pipe require a CA15 welding material

PRODUCT ATTRIBUTES

Material: Copper

Length (L): 254mm

Width (W): 31.75mm


Thickness (T): 1.59mm

Hole Size (HS): 12.7mm

A: 203.2mm

B: 25.4mm

DIAGRAMS

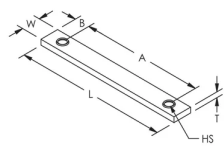

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE