


Non-Insulated Stranded Conductor

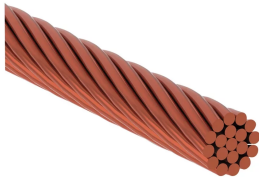

FEATURES

Stranded pure electrolytic copper cable conductors for a variety of applications

Stranded grounded conductor cut into standard lengths for easy field installation

SPECIFICATIONS

Conductor Type: Concentric

Material: Copper

Table 1/2

Catalog Number	Article Number	Number of Wires	Wire Diameter	Diameter (Ø)	Length (L)	Cross Section
A800A09F65		19	2.13mm	10.6 mm	19.81m	67.4mm ²
SCEC120	710900	37	2mm	14.2 mm	500m	120mm ²
SCEC150	710920	37	2.25mm	15.8 mm	500m	150mm ²
SCEC70	197930	19	2.14mm	10.69 mm	500m	70mm ²
SCEC95	197940	19	2.52mm	12.6 mm	500m	95mm ²

Table 2/2


Catalog Number	Article Number	Conductor Size	Unit Weight	Complies With
----------------	----------------	----------------	-------------	---------------

A800A09F65		2/0 Stranded	12.1 kg	
SCEC120	710900	120 mm ² Stranded	515 kg	IEC® EN 62561-2
SCEC150	710920	150 mm ² Stranded	665 kg	
SCEC70	197930	70 mm ² Stranded	31 kg	
SCEC95	197940	95 mm ² Stranded	425 kg	

ADDITIONAL PRODUCT DETAILS

Outer diameter dimensions are approximate.

DIAGRAMS

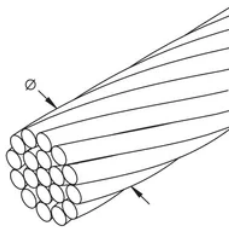

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE