


nVent ERICO Cadweld Plus Rail Joint Bond Kit, Signal, Tab Style

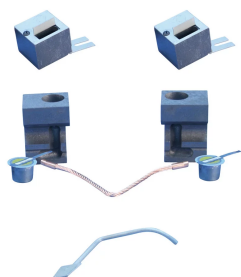

The nVent ERICO Cadweld joint bonds are intended to be welded to the head of the rail profile within the confines of the joint bar. To ensure connection integrity, the attachment shall be made using nVent ERICO Cadweld Plus welding material.

FEATURES

Offers usage of nVent ERICO Cadweld Plus easy electronic ignition

Provides unchanging electrical resistance

Superior corrosion resistance

Easy installation, with minimum installer training required

Simple and highly-portable installation equipment

Equally usable on old, worn, or new rails

Highly durable

SPECIFICATIONS

Rail Type: 85 lb to 141 lb T-Rail Sections

Material: Cadmium Bronze;Copper

Bond Terminal Style: Tab

Table 1/2

Catalog Number	Finish	Grinding Wheels Included	Conductor Size	Bond Length	Length 1 (L1)	Length 2 (L2)
SB20104CWPW 2	Bare, Tinned	Yes	3/16" Bondstrand	165.1mm	115.9 mm	19.1 mm

CatalogNumber	Finish	Grinding Wheels Included	Conductor Size	Bond Length	Length 1 (L1)	Length 2 (L2)
SB20108CWPW 2	Bare, Tinned	Yes	3/16" Bondstrand	247.65mm	198.4 mm	19.1 mm
SB20136CWPW 2	Bare, Tinned	Yes	3/16" Bondstrand	190.5mm	144.5 mm	19.1 mm
SB20175CWP	Bare	No	3/16" Bondstrand	177.8mm	146.1 mm	25.4 mm
SB20175CWPW 2	Bare	Yes	5/16" Bondstrand	177.8mm	146.1 mm	25.4 mm

Table 2/2

Catalog Number	Diameter (Ø)
SB20104CWPW2	4.8 mm
SB20108CWPW2	4.8 mm
SB20136CWPW2	4.8 mm
SB20175CWP	7.9 mm
SB20175CWPW2	7.9 mm

 
ADDITIONAL PRODUCT DETAILS

Kit includes: (60) bonds, (120) PLUSF80 alloy welding material, (2) replacement molds and covers, (1) mold cleaner, and (5) grinding wheels (if applicable).

Kits with grinding wheels include (5) high-performance grain, 4.5" (114 mm) diameter (7/8" arbor), Type 27 depressed center wheels (part number SBG20046) for use with an angle style grinders.

nVent ERICO Cadweld Plus welding material requires electronic control unit for ignition (sold separately).

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE